

Multifamily/Commercial

Wall Mounted • Wet Location Listed **PROGRESS LED**

Description:

LED Outdoor Economy Wall Pack - PMOMP

Specifications:

- Cast aluminum housing
- Dark Bronze powder coat finish with diffused polycarbonate lens
- Standard with integral photocell
- CCT field selectable feature offers 3000K, 4000K and 5000K options
- Field selectable lumen range from 1,930 to 3,325 nominal lumens


Performance:

Input Power	24 W
Input Voltage	Universal 120-277 VAC
Input Frequency	50/60 Hz
Lumens/LPW (Delivered)	3,325/140 (LM-79)
Lumen value based on 4000K selection	
CRI	80 CRI
Life (hours)	50000
EMI/RFI	FCC Part 15, Class B
Warranty	5-year Limited Warranty
Labels	cULus Wet Location Listed
Dimming	0-10VDC
Ingress Protection	IP65
Operating Temperature	-20 °C to 50 °C
THD	<20%
Power Factor	>0.90

PMOMP-CS-BZ



Dimensions:

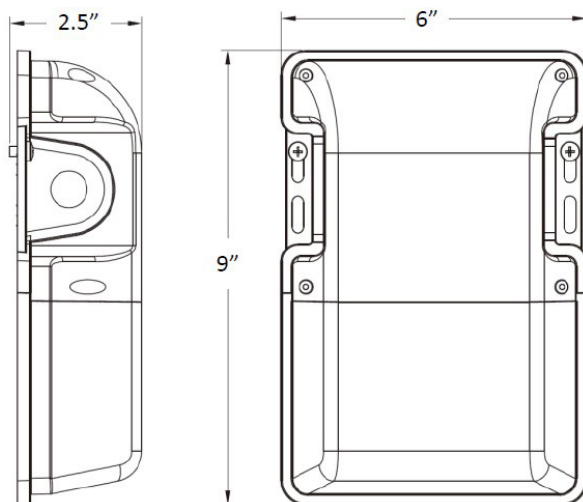

	Low Setting			Mid Setting			High Setting		
	3000K	4000K	5000K	3000K	4000K	5000K	3000K	4000K	5000K
Watts	15W	14W	15W	19W	19W	19W	24W	24W	24W
Lumens	1939	2090	2105	2496	2709	2711	3070	3327	3325
Efficacy	132	145	143	129	143	140	126	140	137