

# Multifamily/Commercial

Wall Mounted • Wet Location Listed **PROGRESS LED**

## Description:

LED Outdoor Commercial Adjustable Wall Pack - PMOWA

## Specifications:

- Rugged die-cast aluminum housing
- Dark Bronze powder coat finish with polycarbonate lens
- CCT field selectable feature offers 3000K, 4000K and 5000K options
- Field selectable lumen range from 3,000 to 5,080 nominal lumens
- Full cutoff when adjusted to lowest angle position
- Accessory field-installed pencil photocontrol is available by ordering PMO-ACSY-PENCILPC

## Performance:


Input Power	35 W
Input Voltage	Universal 120-277 VAC
Input Frequency	50/60 Hz
Lumens/LPW (Delivered)	3,000/3840/5080/133 (LM-79)
Lumen selectable values based on 4000K selection	
CRI	80 CRI
Life (hours)	50000
EMI/RFI	FCC Part 15, Class B
Warranty	5-year Limited Warranty
Labels	cULus Wet Location Listed
Dimming	0-10VDC
Ingress Protection	IP65
Operating Temperature	-40 °C to 50 °C
THD	<20%
Power Factor	>0.90

# PMOWA-1-LS-CS-BZ



## Dimensions:

	<u>5L</u>	<u>10L</u>
<b>Length – L</b>	6.5"	8.5"
<b>Width – W</b>	4"	5"
<b>Height – H</b>	8"	11"
<b>Weight (lbs.)</b>	3	5

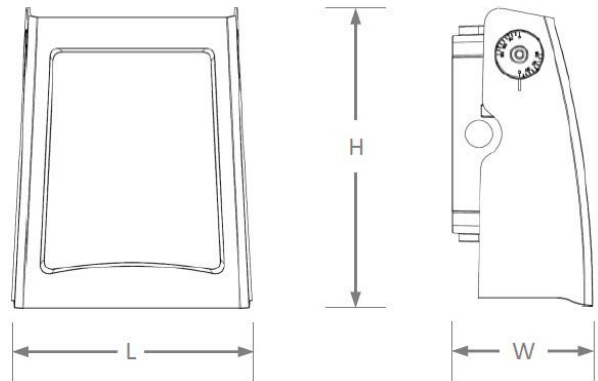

	Low Setting			Mid Setting			High Setting		
	3000K	4000K	5000K	3000K	4000K	5000K	3000K	4000K	5000K
Watts	22W	20W	22W	28W	25W	28W	35W	34W	35W
Lumens	3044	3002	3307	3819	3842	4155	4646	5084	5049
Efficacy	142	154	154	137	151	149	133	151	145