

Multifamily/Commercial

Wall Mounted • Wet Location Listed **PROGRESS LED**

Description:

LED Outdoor Commercial Adjustable Wall Pack - PMOWA

Specifications:

- Rugged die-cast aluminum housing
- Dark Bronze powder coat finish with polycarbonate lens
- CCT field selectable feature offers 3000K, 4000K and 5000K options
- Field selectable lumen range from 6,535 to 10,730 nominal lumens
- Full cutoff when adjusted to lowest angle position
- Accessory field-installed pencil photocontrol is available by ordering PMO-ACSY-PENCILPC

Performance:


Input Power	74 W
Input Voltage	Universal 120-277 VAC
Input Frequency	50/60 Hz
Lumens/LPW (Delivered)	7,025/9030/10730/132 (LM-79)
Lumen selectable values based on 4000K selection	
CRI	80 CRI
Life (hours)	50000
EMI/RFI	FCC Part 15, Class A
Warranty	5-year Limited Warranty
Labels	cULus Wet Location Listed
Dimming	0-10VDC
Ingress Protection	IP65
Operating Temperature	-40 °C to 50 °C
THD	<20%
Power Factor	>0.90

PMOWA-2-LS-CS-BZ



Dimensions:

	<u>5L</u>	<u>10L</u>
Length – L	6.5"	8.5"
Width – W	4"	5"
Height – H	8"	11"
Weight (lbs.)	3	5

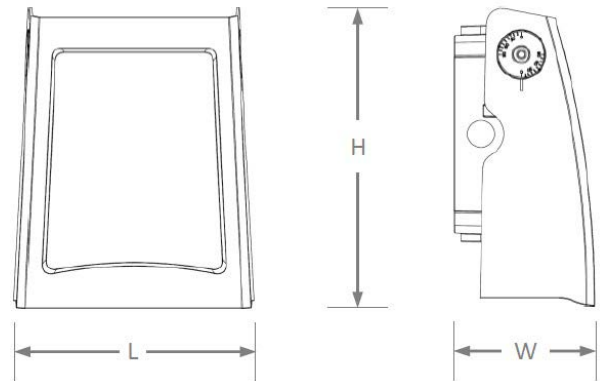

	Low Setting			Mid Setting			High Setting		
	3000K	4000K	5000K	3000K	4000K	5000K	3000K	4000K	5000K
Watts	46W	45W	46W	61W	59W	61W	74W	71W	74W
Lumens	6536	7028	7107	8339	9032	9056	9746	10734	10578
Efficacy	142	157	154	137	153	148	132	150	142