

Project: \_\_\_\_\_  
 Fixture Type: \_\_\_\_\_  
 Location: \_\_\_\_\_  
 Contact: \_\_\_\_\_

## Multifamily/Commercial

Wall Mounted • Wet Location Listed **PROGRESS LED**

### Description:

LED Outdoor Commercial Glass Wall Pack - PMOWP

### Specifications:

- Rugged die-cast aluminum housing
- Dark Bronze powder coat finish with glass lens
- CCT field selectable feature offers 3000K, 4000K and 5000K options
- Field selectable lumen range from 4,510 to 7,290 nominal lumens
- Includes button photocell


### Performance:

Input Power	51 W
Input Voltage	Universal 120-277 VAC
Input Frequency	50/60 Hz
Lumens/LPW (Delivered)	4,665/5850/7290/131 (LM-79)
Lumen selectable values based on 4000K selection	
CRI	80 CRI
Life (hours)	50000
EMI/RFI	FCC Part 15, Class A
Warranty	5-year Limited Warranty
Labels	cULus Wet Location Listed
Dimming	0-10VDC
Ingress Protection	IP65
Operating Temperature	-40 °C to 40 °C
THD	<20%
Power Factor	>0.90

## PMOWP-1-LS-CS-P-BZ



### Dimensions:

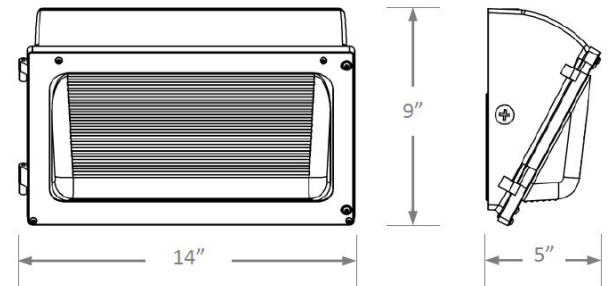

	Low Setting			Mid Setting			High Setting		
	3000K	4000K	5000K	3000K	4000K	5000K	3000K	4000K	5000K
Watts	30W	29W	30W	39W	38W	39W	51W	49W	51W
Lumens	4312	4668	4481	5415	5853	5618	6657	7290	6907
Efficacy	144	151	150	138	150	143	131	149	135