

Multifamily/Commercial

Wall Mounted • Wet Location Listed **PROGRESS LED**

Description:

LED Outdoor Commercial Glass Wall Pack - PMOWP

Specifications:

- Rugged die-cast aluminum housing
- Dark Bronze powder coat finish with glass lens
- CCT field selectable feature offers 3000K, 4000K and 5000K options
- Field selectable lumen range from 6,140 to 10,650 nominal lumens


Performance:

Input Power	76 W
Input Voltage	Universal 120-277 VAC
Input Frequency	50/60 Hz
Lumens/LPW (Delivered)	6,740/8785/10650/129 (LM-79)
Lumen selectable values based on 4000K selection	
CRI	80 CRI
Life (hours)	50000
EMI/RFI	FCC Part 15, Class A
Warranty	5-year Limited Warranty
Labels	cULus Wet Location Listed
Dimming	0-10VDC
Ingress Protection	IP65
Operating Temperature	-40 °C to 40 °C
THD	<20%
Power Factor	>0.90

PMOWP-2-LS-CS-BZ



Dimensions:

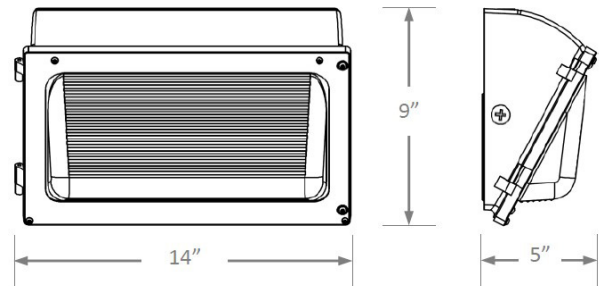

	Low Setting			Mid Setting			High Setting		
	3000K	4000K	5000K	3000K	4000K	5000K	3000K	4000K	5000K
Watts	43W	42W	43W	59W	57W	59W	76W	74W	76
Lumens	6141	6741	6380	7983	8785	8260	9768	10652	10049
Efficacy	142	159	147	135	154	140	129	144	133