

Multifamily/Commercial

Wall Mounted • Wet Location Listed **PROGRESS LED**

Description:

LED Outdoor Commercial Glass Wall Pack - PMOWP

Specifications:

- Rugged die-cast aluminum housing
- Dark Bronze powder coat finish with glass lens
- CCT field selectable feature offers 3000K, 4000K and 5000K options
- Field selectable lumen range from 6,140 to 10,650 nominal lumens
- Includes button photocell


Performance:

| | |
|--|------------------------------|
| Input Power | 76 W |
| Input Voltage | Universal 120-277 VAC |
| Input Frequency | 50/60 Hz |
| Lumens/LPW (Delivered) | 6,740/8785/10650/129 (LM-79) |
| Lumen selectable values based on 4000K selection | |
| CRI | 80 CRI |
| Life (hours) | 50000 |
| EMI/RFI | FCC Part 15, Class A |
| Warranty | 5-year Limited Warranty |
| Labels | cULus Wet Location Listed |
| Dimming | 0-10VDC |
| Ingress Protection | IP65 |
| Operating Temperature | -40 °C to 40 °C |
| THD | <20% |
| Power Factor | >0.90 |

PMOWP-2-LS-CS-P-BZ



Dimensions:

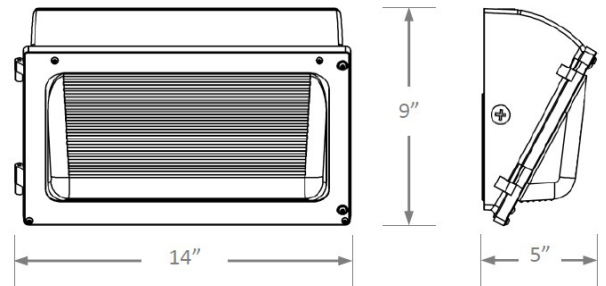

| | Low Setting | | | Mid Setting | | | High Setting | | |
|----------|-------------|-------|-------|-------------|-------|-------|--------------|-------|-------|
| | 3000K | 4000K | 5000K | 3000K | 4000K | 5000K | 3000K | 4000K | 5000K |
| Watts | 43W | 42W | 43W | 59W | 57W | 59W | 76W | 74W | 76 |
| Lumens | 6141 | 6741 | 6380 | 7983 | 8785 | 8260 | 9768 | 10652 | 10049 |
| Efficacy | 142 | 159 | 147 | 135 | 154 | 140 | 129 | 144 | 133 |