

Multifamily/Commercial

Wall Mounted • Wet Location Listed **PROGRESS LED**

Description:

LED Outdoor Commercial Glass Wall Pack - PMOWP

Specifications:

- Rugged die-cast aluminum housing
- Dark Bronze powder coat finish with glass lens
- CCT field selectable feature offers 3000K, 4000K and 5000K options
- Field selectable lumen range from 9,925 to 15,550 nominal lumens
- Includes button photocell


Performance:

Input Power	115 W
Input Voltage	Universal 120-277 VAC
Input Frequency	50/60 Hz
Lumens/LPW (Delivered)	10545/13505/15550/124 (LM-79)
Lumen selectable values based on 4000K selection	
CRI	80 CRI
Life (hours)	50000
EMI/RFI	FCC Part 15, Class A
Warranty	5-year Limited Warranty
Labels	cULus Wet Location Listed
Dimming	0-10VDC
Operating Temperature	-40 °C to 40 °C
THD	<20%
Power Factor	>0.90

PMOWP-3-LS-CS-P-BZ



Dimensions:

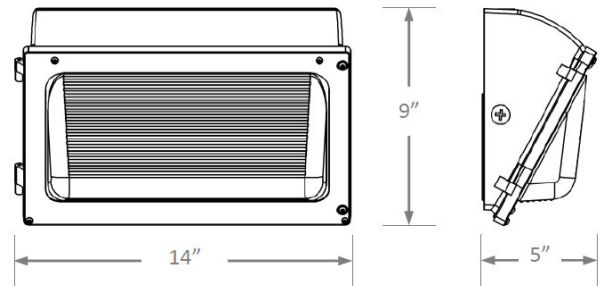

	Low Setting			Mid Setting			High Setting		
	3000K	4000K	5000K	3000K	4000K	5000K	3000K	4000K	5000K
Watts	71W	69W	71W	93W	91W	93W	115W	110W	115W
Lumens	9929	10548	10260	12305	13506	12703	14216	15552	14843
Efficacy	139	153	144	132	149	137	124	141	129