




4 in. Octagon Box, Drawn, 1-1/2 in. Deep, Three 1/2 in. KO's & AC/MC/Flex Clamps, J Bracket

By Raco
Catalog # 157

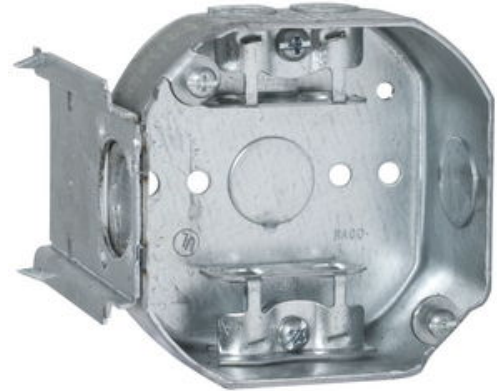

4 in. Octagon Box, Drawn, 1-1/2 in. Deep, Three 1/2 in. KO's & AC/MC/Flex Clamps, J Bracket

Features

- Drawn steel construction with "J" bracket with spurs, slotted holes for toe-nailing
- 4 in. x 1-1/2 in. deep
- BX clamps provided for steel & alum armored cable, MCI cable, MCI-A cable, and flexible conduit
- Supplied with three 1/2 in. knockouts
- Combination Phillips/slotted screw heads
- 15.5 cu. in. capacity

General

Bracket Type	J, for Wood Studs
Ceiling Fan Rated	No
Color	Gray
Drawn or Welded	Drawn
EU RoHS Indicator	Contact Manufacturer
Knockouts	1/2 in
Material	Steel
Size	4 in
Type	Box
UPC	050169001578
Wiring System	Armored Cable/Metal Clad/MCI-A/Flex

Dimensions

Actual Depth	3.31 in
Cubic Capacity	15.5 cu.in
Depth	1.5 in
Fixture Lbs.	50 lb
Height	3.615 in
Raised Ground	No
Weight	0.675 lb
Width	4.032 in

Electrical Ratings

Power Distribution Features	Fire Rated
-----------------------------	------------

Certifications And Compliance

Certified Listed	UL Listed
------------------	-----------

Logistics

Carton Quantity	25
Packaging Type	No Packaging
Pallet Quantity	1800

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - UL COC - E195978- 2](#)
[Certifications - LEED Statement](#)
[Certifications - NEMA OS1](#)
[Certifications - UL COC - E195978-5](#)
[Sales Drawings - 157](#)
[Sales Drawings - RACO-drawn-steel-box-infographic](#)
[SDS - HCC SDS](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-157-SPEC-EN | REV 6/2024