




# 4 in. Octagon Box, Drawn, 2-1/8 in. Deep, Two 1/2 in. KO's & NMSC Clamps, TS Bracket

By RACO  
Catalog # 176

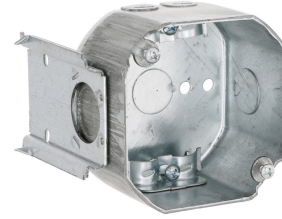

4 in. Octagon Box, Drawn, 2-1/8 in. Deep, Two 1/2 in. KO's & NMSC Clamps, TS Bracket

## Features

- Drawn steel construction with "J" bracket with spurs, slotted holes for toe-nailing and gauging notches at 3/8 in and 1/2 in. and nonmetallic sheathed cable clamps
- 4 in. x 2-1/8 in. deep
- Supplied with three 1/2 in. knockouts
- Combination Phillips/slotted screw heads
- 21.5 cu. in. capacity

## Specifications

Certified Listed	UL Listed
Buy American Compliant	Yes
EU RoHS Indicator	Contact Manufacturer
Buy America(n) Qualified	Buy American Act Compliant (All status valid till December 2026)

## Configuration

Knockouts	1/2 in
Bracket Type	J, for Wood Studs
Bracket Setback	0.625
Number of Gang(s)	1-Gang

## Dimensions

Cubic Capacity	21.5 cu.in
Fixture Lbs.	50 lb.

Depth	2.125 in
Size	4 in
Actual Depth	3.125 in
Raised Ground	No
Width	4.375 in
Weight	0.818 lb.
Height	3.625 in

## General

Wiring System	Nonmetallic Sheathed Cable
Ceiling Fan Rated	No
Color	Gray
Type	Box
Material	Steel
Drawn or Welded	Drawn
UPC	050169001769

## Logistics

Packaging Type	No Packaging
Carton Quantity	25
Pallet Quantity	1625

## Product Assets

- [Catalog \[English\]](#)
- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)