




## 4 in. Octagon Box, Drawn, 2-1/8 in. Deep with NMSC Clamps and TS Bracket

By Raco  
Catalog # 177

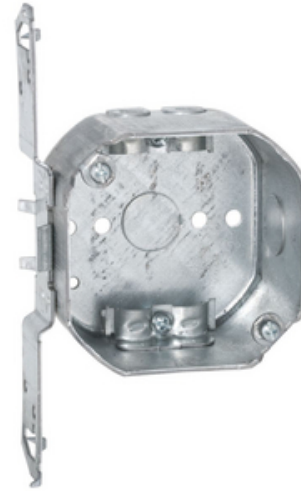

4 in. Octagon Box, Drawn, 2-1/8 in. Deep with NMSC Clamps and TS Bracket

### Features

- Drawn steel construction with "TS" side-mount bracket and L clamps for nonmetallic sheathed cable
- 4 in. x 2-1/8 in. deep
- Supplied with two 1/2 in. knockouts
- Combination Phillips/slotted screw heads
- 21.5 cu. in. capacity

### General

Bracket Setback	0.5
Bracket Type	TS, for Metal or Wood Studs
Ceiling Fan Rated	No
Color	Gray
Drawn or Welded	Drawn
EU RoHS Indicator	Contact Manufacturer
Knockouts	1/2 in
Material	Steel
Number of Gang(s)	2-Gang
Size	4 in
Type	Box
UPC	050169001776
Wiring System	Nonmetallic Sheathed Cable

### Dimensions

Actual Depth	2.188 in
Cubic Capacity	21.5 cu.in
Depth	2.125 in
Fixture Lbs.	50 lb
Height	7 in
Raised Ground	No
Weight	0.796 lb
Width	3.875 in

### Certifications And Compliance

Certified Listed	UL Listed
------------------	-----------

### Logistics

Carton Quantity	25
Packaging Type	No Packaging
Pallet Quantity	1750

### Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)  
[Certifications - LEED Statement](#)  
[Certifications - NEMA OS1](#)  
[Certifications - UL COC - E195978-21](#)  
[Sales Drawings - RACO-drawn-steel-box-infographic](#)  
[SDS - HCC SDS](#)  
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
RACO-177-SPEC-EN | REV 6/2024