




## 4 in. Square Box, Welded, 1-1/2 in. Deep with One 1/2 and Twelve 3/4 in. KO's

By Raco  
Catalog # 181

4 in. Square Box, Welded, 1-1/2 in. Deep with One 1/2 and Twelve 3/4 in. KO's

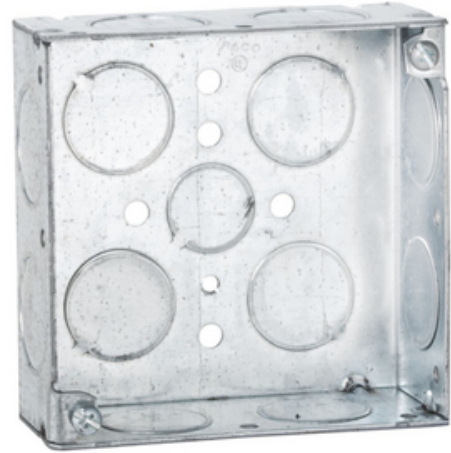

### Features

- Combination screw heads allow quick installation
- Welded construction
- One 1/2 in. and twelve 3/4 in. knockouts
- UL Listed
- 21.0 cu. in. capacity
- Acceptable in 2-hour fire rated walls

### General

Bracket Type	No Bracket
Color	Gray
Drawn or Welded	Welded
EU RoHS Indicator	Contact Manufacturer
Fire Resistance	Yes
Knockouts	1/2 in.;3/4 in
Material	Steel
Number of Gang(s)	2-Gang
Type	Box
UPC	050169001813
Wiring System	Conduit

### Dimensions

Actual Depth	1.563 in
Cubic Capacity	21 cu.in
Depth	1.5 in
Height	4 in
Raised Ground	No
Weight	0.706 lb
Width	4 in

### Electrical Ratings

Power Distribution Features	Fire Rated
-----------------------------	------------

### Certifications And Compliance

Certified Listed	UL Listed
------------------	-----------

### Logistics

Carton Quantity	50
Packaging Type	No Packaging
Pallet Quantity	2750

### Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)  
[Certifications - UL COC - E195978-17](#)  
[Certifications - UL COC - E195978- 9](#)  
[Certifications - LEED Statement](#)  
[Certifications - NEMA OS1](#)  
[Sales Drawings - 181](#)  
[Sales Drawings - RACO-welded-steel-box-infographic](#)  
[SDS - HCC\\_SDS](#)  
[Terms and Conditions - HCC Terms & Conditions](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
RACO-181-SPEC-EN | REV 6/2024