




2-1/2 in. Rigid/IMC Compression Coupling

By Raco
Catalog # 1830

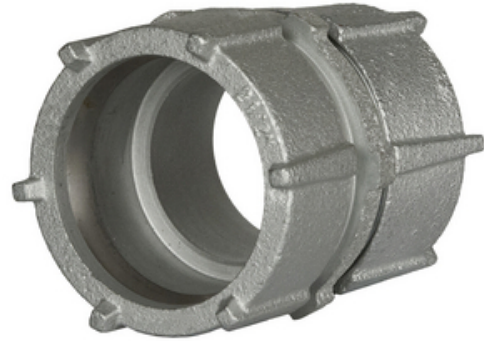

2-1/2 in. Rigid/IMC Compression Coupling

Features

- Malleable iron construction ensures mechanical protection for the raceway
- Zinc-electroplated for added corrosion protection
- Hex compression nuts assure easy wrench installation
- Available in trade sizes 1/2 in. through 4 in.

General

Conduit Type	Rigid/IMC
Connector Type	Compression
EU RoHS Indicator	Contact Manufacturer
Fitting Type	Couplings
Material	Steel/Malleable Iron
UPC	050169018309

Dimensions

Dimensions	5.75 in x 3.938 in x 3.938 in
Height	3.938 in
Length	5.75 in
Trade Size	2-1/2 in
Weight	2.528 lb
Width	3.938 in

Certifications And Compliance

Certified Listed	<ul style="list-style-type: none">• UL Listed• CSA Certified
Industry Standard(s)	UL 514B

Logistics

Carton Quantity	5
Minimum Pack Quantity	5
Pallet Quantity	560

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Product Logo - Conduit](#)
[Sales Drawings - 1830](#)
[SDS - HCC_SDS](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
RACO-1830-SPEC-EN | REV 6/2024