




3-1/2 in. Rigid/IMC Compression Coupling

By Raco
Catalog # 1834

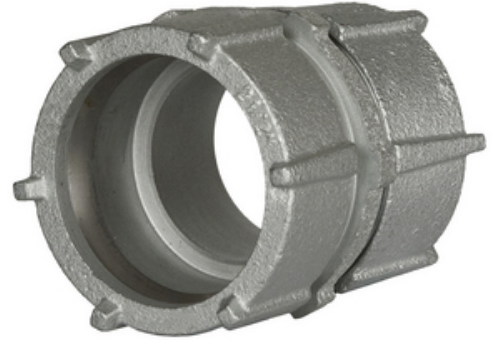

3-1/2 in. Rigid/IMC Compression Coupling

Features

- Malleable iron construction ensures mechanical protection for the raceway
- Zinc-electroplated for added corrosion protection
- Hex compression nuts assure easy wrench installation
- Available in trade sizes 1/2 in. through 4 in.

General

Catalog Number	1834
Conduit Type	Rigid/IMC
Connector Type	Compression
EU RoHS Indicator	Contact Manufacturer
Fitting Type	Couplings
Material	Steel/Malleable Iron
UPC	050169018347

Dimensions

Dimensions	6 in x 5.203 in x 5.203 in
Height	5.203 in
Length	6 in
Trade Size	3-1/2 in
Weight	4.15 lb
Width	5.203 in

Certifications And Compliance

Certified Listed	UL Listed
	CSA Certified
Industry Standard(s)	UL 514B

Logistics

Carton Quantity	1
Minimum Pack Quantity	1
Pallet Quantity	336

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Product Logo - Conduit](#)
[Sales Drawings - 1834 Customer Drawing](#)
[SDS - HCC SDS](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-1834-SPEC-EN | REV 6/2024