




4 in. Square Box, Welded, 1-1/2 in. Deep with 13 Knockouts, Raised Ground, 8 in. #12 Solid Copper Pigtail, UBS, HM Bracket

By Raco
Catalog # 189H

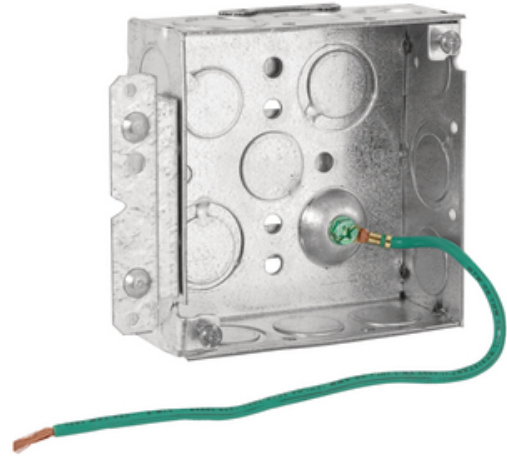

4 in. Square Box, Welded, 1-1/2 in. Deep with Eight 1/2 in. KO's & Five TKO's, Raised Ground, 8 in. #12 Solid Copper Pigtail, UBS, HM Bracket

Features

- TKO knockout design provides installation flexibility
- UBS integrated support provides the bracing on back of box for wall cavities between 2-1/2 in - 6 in. thickness, H/M
- Welded construction
- Eight 1/2 in. knockouts and five TKO knockouts
- UL Listed
- 21.0 cu. in. capacity
- Raised ground, 8 in. #12 Solid Copper pigtail
- Acceptable in 2-hour fire rated walls

General

Bracket Setback	0.375
Bracket Type	H, for Metal or Wood Studs
Color	Gray
Drawn or Welded	Welded
EU RoHS Indicator	Contact Manufacturer
Fire Resistance	Yes
Knockouts	1/2 in; 1/2 - 3/4 in Combination (TKO)
Material	Steel
Number of Gang(s)	2-Gang
Type	Box
UPC	050169500002
Wiring System	Conduit

Dimensions

Actual Depth	2.063 in
Cubic Capacity	21 cu.in
Depth	1.5 in
Height	4 in
Raised Ground	Yes
Weight	0.84 lb
Width	4.913 in

Electrical Ratings

Power Distribution Features Fire Rated

Certifications And Compliance

Certified Listed UL Listed

Logistics

Carton Quantity 20
Packaging Type No Packaging
Pallet Quantity 1600

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - UL COC - E195978-1](#)
[Certifications - LEED Statement](#)
[Certifications - NEMA OS1](#)
[Sales Drawings - 189H](#)
[Sales Drawings - RACO-welded-steel-box-infographic](#)
[SDS - HCC SDS](#)
[Sell Sheets - H&M Series](#)
[Terms and Conditions - HCC Terms & Conditions](#)
[Video - RACO: H&M Series Installation](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-189H-SPEC-EN | REV 6/2024