




4 in. Square Box, Welded, 1-1/2 in. Deep with Eight 1/2 in. KO's & Five TKO's, Raised Ground, 10 in., UBS, HM Bracket

By Raco
Catalog # 189HWP

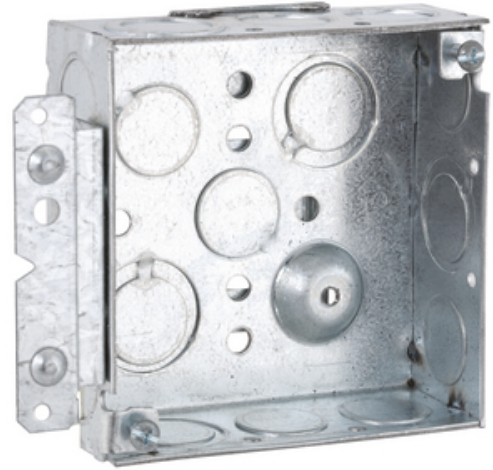

4 in. Square Box, Welded, 1-1/2 in. Deep with Eight 1/2 in. KO's & Five TKO's, Raised Ground, 10 in., UBS, HM Bracket

Features

- TKO knockout design provides installation flexibility
- UBS integrated support provides the bracing on back of box for wall cavities between 2-1/2 in - 6 in. thickness, H/M
- Welded construction
- Eight 1/2 in. knockouts and five TKO knockouts
- UL Listed
- 21.0 cu. in. capacity
- Raised ground
- Acceptable in 2-hour fire rated walls

General

| | |
|-------------------|--|
| Bracket Setback | 0.375 |
| Bracket Type | H, for Metal or Wood Studs |
| Color | Gray |
| Drawn or Welded | Welded |
| EU RoHS Indicator | Contact Manufacturer |
| Fire Resistance | Yes |
| Knockouts | 1/2 in.;1/2 - 3/4 in Combination (TKO) |
| Material | Steel |
| Number of Gang(s) | 2-Gang |
| Type | Box |
| UPC | 050169500354 |
| Wiring System | Conduit |

Dimensions

| | |
|----------------|----------|
| Actual Depth | 2.063 in |
| Cubic Capacity | 21 cu.in |
| Depth | 1.5 in |
| Height | 4 in |
| Raised Ground | Yes |
| Weight | 0.82 lb |
| Width | 4.913 in |

Electrical Ratings

Power Distribution Features Fire Rated

Certifications And Compliance

Certified Listed UL Listed

Logistics

| | |
|-----------------|--------------|
| Carton Quantity | 20 |
| Packaging Type | No Packaging |
| Pallet Quantity | 1600 |

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - UL COC - E195978-1](#)
[Certifications - LEED Statement](#)
[Certifications - NEMA OS1](#)
[Sales Drawings - 189HWP](#)
[Sales Drawings - RACO-welded-steel-box-infographic](#)
[SDS - HCC SDS](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-189HWP-SPEC-EN | REV 6/2024