




## 4 in. Square Box, Welded, 1-1/2 in. Deep with 10 Knockouts, Raised Ground, 8 in. #12 Solid Copper Pigtail, UBS, HM Bracket

By Raco  
Catalog # 189M

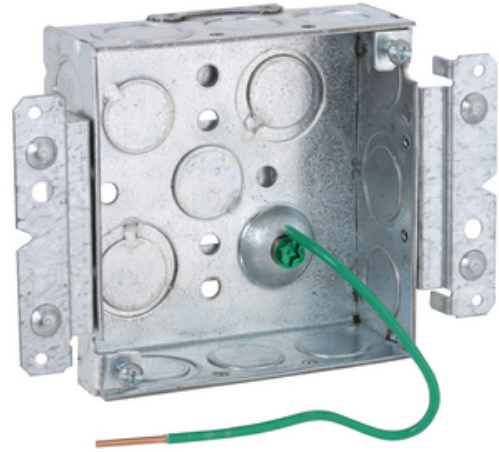

4 in. Square Box, Welded, 1-1/2 in. Deep with Six 1/2 in. KO's & Four TKO's, Raised Ground, 8 in. #12 Solid Copper Pigtail, UBS, HM Bracket

### Features

- TKO knockout design provides installation flexibility
- UBS integrated support provides the bracing on back of box for wall cavities between 2-1/2 in - 6 in. thickness, H/M
- Welded construction
- Six 1/2 in. knockouts and four TKO knockouts
- UL Listed
- 21.0 cu. in. capacity
- Raised ground, 8 in. #12 Solid Copper pigtail
- Acceptable in 2-hour fire rated walls

### General

Bracket Setback	0.375
Bracket Type	M, for Metal or Wood Studs
Drawn or Welded	Welded
EU RoHS Indicator	Contact Manufacturer
Fire Resistance	Yes
Knockouts	1/2 in; 1/2 - 3/4 in Combination (TKO)
Material	Steel
Type	Box
UPC	050169500019
Wiring System	Conduit

### Dimensions

Actual Depth	2.063 in
Cubic Capacity	21 cu.in
Depth	1.5 in
Height	4 in
Raised Ground	Yes
Weight	0.87 lb
Width	5.86 in

### Certifications And Compliance

Certified Listed	UL Listed
------------------	-----------

### Logistics

Carton Quantity	20
Packaging Type	No Packaging
Pallet Quantity	1600

### Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)  
[Certifications - UL COC - E195978-1](#)  
[Certifications - LEED Statement](#)  
[Certifications - NEMA OS1](#)  
[Sales Drawings - 189M](#)  
[SDS - HCC SDS](#)  
[Sell Sheets - H&M Series](#)  
[Terms and Conditions - HCC Terms & Conditions](#)  
[Video - RACO: H&M Series Installation](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
RACO-189M-SPEC-EN | REV 6/2024