




## 4 in. Square Box, Welded, 1-1/2 in. Deep with Nine 1/2 in. KO's and Five TKO's, Flush, B Bracket

By Raco  
Catalog # 193

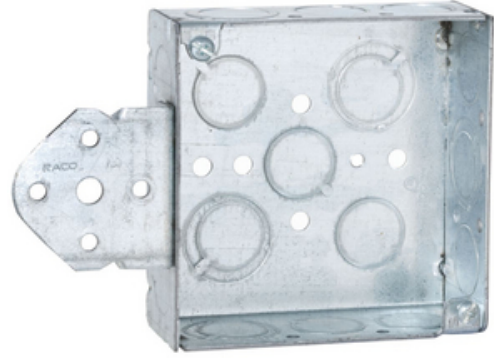

4 in. Square Box, Welded, 1-1/2 in. Deep with Nine 1/2 in. KO's and Five TKO's, Flush, B Bracket

### Features

- TKO knockout design provides installation flexibility
- B style bracket, flush
- Welded construction
- Nine 1/2 in. knockouts and Five TKO knockouts
- UL Listed
- 21.0 cu. in. capacity
- Acceptable in 2-hour fire rated walls

### General

Bracket Type	B, for Wood Studs
Catalog Number	193
Drawn or Welded	Welded
EU RoHS Indicator	Contact Manufacturer
Fire Resistance	Yes
Knockouts	1/2 in;1/2 - 3/4 in Combination (TKO)
Material	Steel
Type	Box
UPC	050169901939
Wiring System	Conduit

### Dimensions

Actual Depth	1.563 in
Cubic Capacity	21 cu.in
Depth	1.5 in
Height	4 in
Raised Ground	No
Weight	0.788 lb
Width	6 in

### Certifications And Compliance

Certified Listed	UL Listed
------------------	-----------

### Logistics

Carton Quantity	25
Packaging Type	No Packaging
Pallet Quantity	2000

### Product Assets

[3D Product View - RACO\\_8193](#)  
[Catalogs - RACO / TayMac / Bell Full Catalog](#)  
[Certifications - UL COC - E195978-18](#)  
[Certifications - LEED Statement](#)  
[Certifications - NEMA OS1](#)  
[Sales Drawings - 193](#)  
[SDS - HCC\\_SDS](#)  
[Terms and Conditions - HCC Terms & Conditions](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
RACO-193-SPEC-EN | REV 6/2024