




## 4 in. Square Box, Welded, 1-1/2 in. Deep with AC/MC/Flex Clamps, Five 1/2 in. KO's and Two TKO's

By Raco  
Catalog # 213

4 in. Square Box, Welded, 1-1/2 in. Deep with AC/MC/Flex Clamps, Five 1/2 in. KO's and Two TKO's

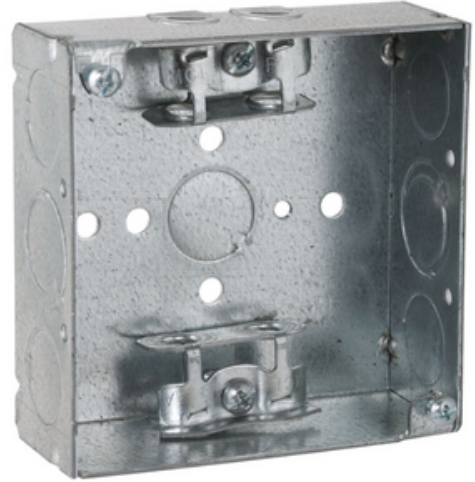

### Features

- Use with AC/MC or flexible cable
- Combination screw heads allow quick installation
- Welded construction
- Five 1/2 in. knockouts, 2 TKO knockouts, and 4 cable pryouts
- UL Listed
- 21.0 cu. in. capacity

### General

Bracket Type	No Bracket
Drawn or Welded	Welded
EU RoHS Indicator	Contact Manufacturer
Fire Resistance	Yes
Knockouts	1/2 in.; 1/2 - 3/4 in Combination (TKO)
Material	Steel
Type	Box
UPC	050169902134
Wiring System	Armored Cable/Metal Clad/MCI-A/Flex

### Dimensions

Actual Depth	1.563 in
Cubic Capacity	21 cu.in
Depth	1.5 in
Height	4 in
Raised Ground	No
Weight	0.777 lb
Width	4 in

### Certifications And Compliance

Certified Listed	UL Listed
------------------	-----------

### Logistics

Carton Quantity	50
Packaging Type	No Packaging
Pallet Quantity	2500

### Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)  
[Certifications - LEED Statement](#)  
[Certifications - NEMA OS1](#)  
[Sales Drawings - 213](#)  
[SDS - HCC SDS](#)  
[Terms and Conditions - HCC Terms & Conditions](#)



**A Hubbell brand**

©2024 Hubbell Incorporated. All rights reserved  
RACO-213-SPEC-EN | REV 6/2024