




4 in. Square Box, Welded, 1-1/2 in. Deep with AC/MC/Flex Clamps, Five 1/2 in. KO's and Two TKO's, UBS, HM Bracket

By Raco
Catalog # 213HWP

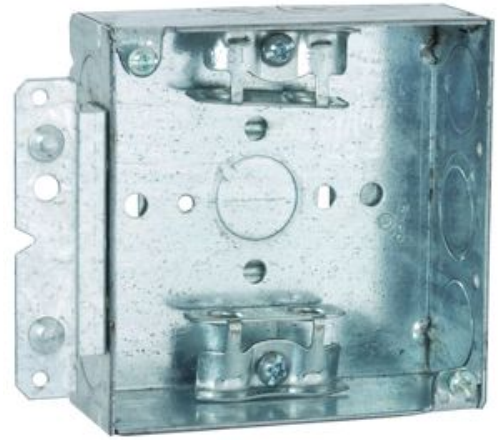

4 in. Square Box, Welded, 1-1/2 in. Deep with AC/MC/Flex Clamps, Five 1/2 in. KO's and Two TKO's, UBS, HM Bracket

Features

- Use with AC/MC or flexible cable
- Combination screw heads allow quick installation
- Welded construction
- Five 1/2 in. knockouts, 2 TKO knockouts, and 4 cable pryouts
- UL Listed
- 21.0 cu. in. capacity
- UBS integrated support provides bracing on back of box for wall cavities between 2-1/2 in - 6 in. thickness, HM

General

Bracket Setback	0.375
Bracket Type	H, for Metal or Wood Studs
Color	Gray
Drawn or Welded	Welded
EU RoHS Indicator	Contact Manufacturer
Fire Resistance	Yes
Knockouts	1/2 in; 1/2 - 3/4 in Combination (TKO)
Material	Steel
Number of Gang(s)	2-Gang
Type	Box
UPC	050169502136
Wiring System	Armored Cable/Metal Clad/MCI-A/Flex

Dimensions

Actual Depth	2.063 in
Cubic Capacity	21 cu.in
Depth	1.5 in
Height	4 in
Raised Ground	No
Weight	0.777 lb
Width	4.915 in

Electrical Ratings

Power Distribution Features	Fire Rated
-----------------------------	------------

Certifications And Compliance

Certified Listed UL Listed

Logistics

Carton Quantity	20
Packaging Type	No Packaging
Pallet Quantity	1600

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - LEED Statement](#)
[Certifications - NEMA OS1](#)
[SDS - HCC SDS](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-213HWP-SPEC-EN | REV 6/2024