




4 in. Square Box, Welded, 1-1/2 in. Deep with AC/MC/Flex Clamps, Three 1/2 in. KO's and One TKO, UBS, FS Bracket, Flush

By Raco
Catalog # 218

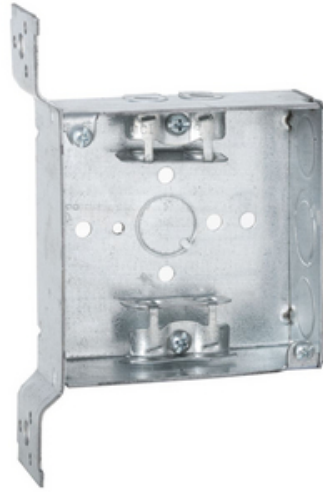

4 in. Square Box, Welded, 1-1/2 in. Deep with AC/MC/Flex Clamps, Three 1/2 in. KO's and One TKO, UBS, FS Bracket, Flush

Features

- Use with AC/MC or flexible cable
- Combination screw heads allow quick installation
- Welded construction
- Three 1/2 in. knockouts, 1 TKO knockout, and 4 cable pryouts
- UL Listed
- 21.0 cu. in. capacity
- FS style bracket, flush

General

Bracket Type	FS, for Metal or Wood Studs
Drawn or Welded	Welded
EU RoHS Indicator	Contact Manufacturer
Fire Resistance	Yes
Knockouts	1/2 in;1/2 - 3/4 in Combination (TKO)
Material	Steel
Type	Box
UPC	050169902189
Wiring System	Armored Cable/Metal Clad/MCI-A/Flex

Dimensions

Actual Depth	1.563 in
Cubic Capacity	21 cu.in
Depth	1.5 in
Height	6.875 in
Raised Ground	No
Weight	0.872 lb
Width	4.375 in

Certifications And Compliance

Certified Listed	UL Listed
------------------	-----------

Logistics

Carton Quantity	25
Packaging Type	No Packaging
Pallet Quantity	1650

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - UL COC - E195978-18](#)
[Certifications - LEED Statement](#)
[Certifications - NEMA OS1](#)
[Sales Drawings - 218](#)
[SDS - HCC SDS](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-218-SPEC-EN | REV 6/2024