



4 in. Square Box, Welded, 1-1/2 in. Deep with AC/MC/Flex Clamps, Three 1/2 in. KO's, BOX-LOC®,MS Bracket, Flush

By Raco
Catalog # 229

4 in. Square Box, Welded, 1-1/2 in. Deep with AC/MC/Flex Clamps, Three 1/2 in. KO's, BOX-LOC®,MS Bracket, Flush

Features


- Use with AC/MC or flexible cable
- Combination screw heads allow quick installation
- Welded construction
- Three 1/2 in. knockouts and 4 pryouts
- Provided with far-side support, model #978
- 21.0 cu. in. capacity

General

Bracket Type	MS, for Metal Studs
Catalog Number	229
Color	Gray
Drawn or Welded	Welded
EU RoHS Indicator	Contact Manufacturer
Fire Resistance	Yes
Knockouts	1/2 in
Material	Steel
Number of Gang(s)	2-Gang
Type	Box
UPC	050169002292
Wiring System	Armored Cable/Metal Clad/MCI-A/Flex

Dimensions

Actual Depth	2.115 in
Cubic Capacity	21 cu.in
Depth	1.5 in

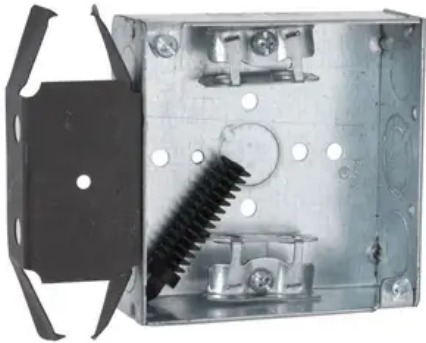

Height	4.5 in
Raised Ground	No
Weight	0.897 lb
Width	5.625 in

Electrical Ratings

Power Distribution Features	Fire Rated
-----------------------------	------------

Certifications And Compliance

Buy American Compliant	Contact Manufacturer
Certified Listed	UL Listed

Logistics

Carton Quantity	25
Packaging Type	No Packaging

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - NEMA OS1](#)
[Certifications - LEED Statement](#)
[Sales Drawings - 229 Customer Drawing](#)
[SDS - HCC SDS](#)
[Sell Sheets - Box Positioning Products](#)
[Sell Sheets - BOX-LOC Metal Stud Bracketed Boxes](#)
[Specifications - 229](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand