




## 4 in. Square Box, Welded, 1-1/2 in. Deep with AC/MC/Flex Clamps, Three 1/2 in. KO's, BOX-LOC®,MS Bracket, Flush

By Raco  
Catalog # 229

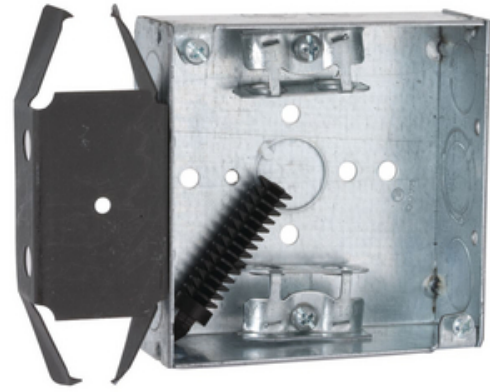

4 in. Square Box, Welded, 1-1/2 in. Deep with AC/MC/Flex Clamps, Three 1/2 in. KO's, BOX-LOC®,MS Bracket, Flush

### Features

- Use with AC/MC or flexible cable
- Combination screw heads allow quick installation
- Welded construction
- Three 1/2 in. knockouts and 4 pryouts
- Provided with far-side support, model #978
- 21.0 cu. in. capacity

### General

Bracket Type	MS, for Metal Studs
Color	Gray
Drawn or Welded	Welded
EU RoHS Indicator	Contact Manufacturer
Fire Resistance	Yes
Knockouts	1/2 in
Material	Steel
Number of Gang(s)	2-Gang
Type	Box
UPC	050169002292
Wiring System	Armored Cable/Metal Clad/MCI-A/Flex

### Dimensions

Actual Depth	2.115 in
Cubic Capacity	21 cu.in
Depth	1.5 in
Height	4.5 in
Raised Ground	No
Weight	0.897 lb
Width	5.625 in

### Electrical Ratings

Power Distribution Features	Fire Rated
-----------------------------	------------

### Certifications And Compliance

Certified Listed	UL Listed
------------------	-----------

### Logistics

Carton Quantity	25
Packaging Type	No Packaging
Pallet Quantity	1650

### Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)  
[Certifications - LEED Statement](#)  
[Certifications - NEMA OS1](#)  
[Sales Drawings - 229](#)  
[Sales Drawings - RACO-welded-steel-box-infographic](#)  
[SDS - HCC SDS](#)  
[Sell Sheets - Box Positioning Products](#)  
[Sell Sheets - BOX-LOC Metal Stud Bracketed Boxes](#)  
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
RACO-229-SPEC-EN | REV 6/2024