


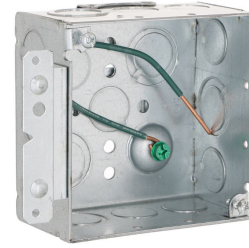

4 in. Square Box, Welded, 2-1/8 in. Deep, Sixteen Knockouts, Raised Ground, 8 in. #12 Solid Copper Pigtail, UBS, HM Bracket

By RACO
Catalog # 232H



4 in. Square Box, Welded, 2-1/8 in. Deep, Ten 1/2 in. KO's and Six TKO's, Raised Ground, 8 in. #12 Solid Copper Pigtail, UBS, HM Bracket

Features

- UBS integrated support provides bracing on back of box for wall cavities between 2-1/2 in - 6 in. thickness, H/M
- Combination screw heads allow quick installation
- Welded construction
- Ten 1/2 in. knockouts and six TKO knockouts
- UL Listed
- 30.3 cu. in. capacity
- Raised ground, 8 in. #12 solid copper pigtail
- Acceptable in 2-hour fire rated walls

Specifications

Certified Listed	UL Listed
Buy American Compliant	No
EU RoHS Indicator	Contact Manufacturer

Configuration

Knockouts	<ul style="list-style-type: none"> • 1/2 in • 1/2 - 3/4 in Combination (TKO)
Bracket Type	H, for Metal or Wood Studs
Bracket Setback	0.375
Number of Gang(s)	2-Gang

Dimensions

Cubic Capacity	30.3 cu.in
----------------	------------

Depth	2.125 in
Size	4 in
Actual Depth	2.676 in
Raised Ground	Yes
Width	4.915 in
Weight	1 lb.
Height	4 in

General

Wiring System	Conduit
Color	Gray
Type	Box
Fire Resistance	Yes
Material	Steel
Drawn or Welded	Welded
UPC	050169500033

Logistics

Carton Quantity	25
Pallet Quantity	1375

Product Assets

- [Catalog \[English\]](#)
- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)