




4 in. Square Box, Welded, 2-1/8 in. Deep, Ten 1/2 in. KO's and Six TKO's, Raised Ground, UBS, HM Bracket

By Raco
Catalog # [232HWP](#)

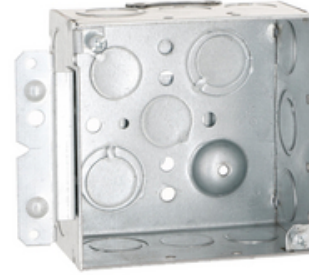

4 in. Square Box, Welded, 2-1/8 in. Deep, Ten 1/2 in. KO's and Six TKO's, Raised Ground, UBS, HM Bracket

Features

- UBS integrated support provides bracing on back of box for wall cavities between 2-1/2 in - 6 in. thickness, H/M
- Combination screw heads allow quick installation
- Welded construction
- Ten 1/2 in. knockouts and six TKO knockouts
- UL Listed
- 30.3 cu. in. capacity
- Raised ground
- Acceptable in 2-hour fire rated walls

General

| | |
|-------------------|----------------------------------------|
| Bracket Setback | 0.375 |
| Bracket Type | H, for Metal or Wood Studs |
| Drawn or Welded | Welded |
| EU RoHS Indicator | Contact Manufacturer |
| Fire Resistance | Yes |
| Knockouts | 1/2 in; 1/2 - 3/4 in Combination (TKO) |
| Material | Steel |
| Type | Box |
| UPC | 050169500361 |
| Wiring System | Conduit |

Dimensions

| | |
|----------------|------------|
| Actual Depth | 2.676 in |
| Cubic Capacity | 30.3 cu.in |
| Depth | 2.125 in |
| Height | 4.03 in |
| Raised Ground | Yes |
| Weight | 0.97 lb |
| Width | 4.91 in |

Certifications And Compliance

| | |
|------------------|-----------|
| Certified Listed | UL Listed |
|------------------|-----------|

Logistics

| | |
|-----------------|------|
| Carton Quantity | 25 |
| Pallet Quantity | 1375 |

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - UL COC - E195978-5](#)
[Certifications - LEED Statement](#)
[Certifications - NEMA OS1](#)
[Sales Drawings - 232HWP](#)
[Sales Drawings - RACO-welded-steel-box-infographic](#)
[SDS - HCC SDS](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-232HWP-SPEC-EN | REV 6/2024