


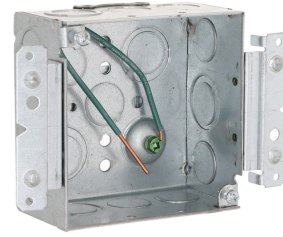

4 in. Square Box, Welded, 2-1/8 in. 16 Knockouts, Raised Ground, 8 in. #12 Solid Copper Pigtail, UBS, HM Bracket

By RACO
Catalog # 232M



4 in. Square Box, Welded, 2-1/8 in. Deep, Ten 1/2 in. KO's and Six TKO's, Raised Ground, 8 in. #12 Solid Copper Pigtail, UBS, HM Bracket

Features

- UBS integrated support provides bracing on back of box for wall cavities between 2-1/2 in - 6 in. thickness, H/M
- Combination screw heads allow quick installation
- Welded construction
- Ten 1/2 in. knockouts and six TKO knockouts
- UL Listed
- 30.3 cu. in. capacity
- Raised ground, 8 in. #12 Solid Copper pigtail
- Acceptable in 2-hour fire rated walls

Specifications

Certified Listed	UL Listed
Buy American Compliant	No
EU RoHS Indicator	Contact Manufacturer
Buy America(n) Qualified	TAA Compliant (All status valid till December 2026)

Configuration

Knockouts	<ul style="list-style-type: none"> • 1/2 in • 1/2 - 3/4 in Combination (TKO)
Bracket Type	M, for Metal or Wood Studs
Bracket Setback	0.375
Number of Gang(s)	2-Gang

Dimensions

Cubic Capacity	30.3 cu.in
Depth	2.125 in
Size	4 in
Actual Depth	2.676 in
Raised Ground	Yes
Width	5.86 in
Weight	1.03 lb.
Height	4 in

General

Wiring System	Conduit
Color	Gray
Type	Box
Fire Resistance	Yes
Material	Steel
Drawn or Welded	Welded
UPC	050169500040

Logistics

Carton Quantity	25
Pallet Quantity	1375

Product Assets

- [Catalog \[English\]](#)
- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)