


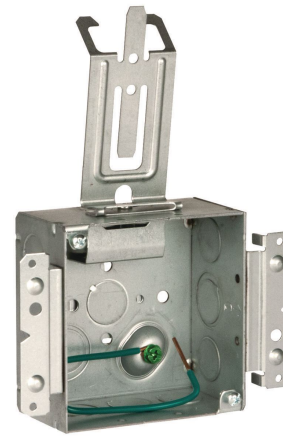

4 in. Square Box, Welded with STAB-iT® Series Connector, 2-1/8 in. Deep, Raised Ground, Pigtail, UBS, M Bracket, Cable Mgmt Clip

By RACO
Catalog # 232MSCM

4 in. Square Box, Welded with STAB-IT® Connector, 2-1/8 in. Deep, Raised Ground, 8 in. #12 Solid Copper Pigtail, UBS, M Bracket, Cable Management Clip



Features

- Welded steel construction with "UBS" support with preset bend points to work with wall thickness 2-1/2 to 6 in., "M" brackets on both sides of the box, STAB-IT® connector and cable management clip
- 4 in. square x 2-1/8 in. deep
- Designed for quick installation of flex, MC, MCI, MCI-A, AC, and HCF Cable
- TKO® Knockouts allows for design and installatin flexibility
- Supplied with seven 1/2 in. and four 1/2-3/4 in. TKO® knockouts
- Combination Phillips/slotted screw heads
- 30.3 cu. in. capacity
- Includes 8 in. #12 solid copper ground pigtail
- Acceptable for use in 2-hour fire rated walls

Specifications

Certified Listed	UL Listed
Buy America(n) Qualified	Contact Manufacturer

Configuration

Knockouts	<ul style="list-style-type: none"> • 1/2 in • 1/2 - 3/4 in Combination (TKO)
Bracket Type	M, for Metal or Wood Studs
Number of Gang(s)	2-Gang

Dimensions

Cubic Capacity	30.3 cu.in
Depth	2.125 in
Size	4 in
Actual Depth	2.64 in
Raised Ground	Yes
Width	5.86 in
Weight	1.212 lb.
Height	4.17 in

General

Series	STAB-IT®
Color	Gray
Type	Box
Fire Resistance	Yes
Material	Steel
Drawn or Welded	Welded
UPC	050169922323

Logistics

Carton Quantity	25
Pallet Quantity	1375

Product Assets

- [Catalog \[English\]](#)
- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Installation Manual \[English\]](#)