




4 in. Square Box, Welded with STAB-IT® Connector, 2-1/8 in. Deep, Raised Ground, Pigtail, UBS, M Bracket, Cable Mgmt Clip

By Raco
Catalog # 232MSCM

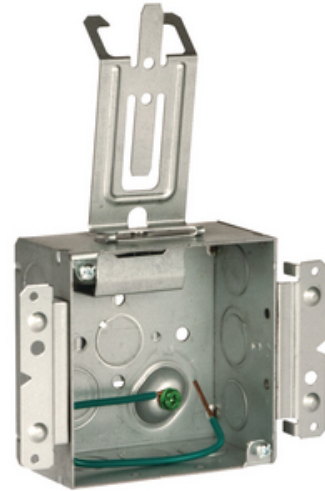

4 in. Square Box, Welded with STAB-IT® Connector, 2-1/8 in. Deep, Raised Ground, 8 in. #12 Solid Copper Pigtail, UBS, M Bracket, Cable Management Clip

Features

- Welded steel construction with "UBS" support with preset bend points to work with wall thickness 2-1/2 to 6 in., "M" brackets on both sides of the box, STAB-IT® connector and cable management clip
- 4 in. square x 2-1/8 in. deep
- Designed for quick installation of flex, MC, MCI, MCI-A, AC, and HCF Cable
- TKO® Knockouts allows for design and installatin flexibility
- Supplied with seven 1/2 in. and four 1/2-3/4 in. TKO® knockouts
- Combination Phillips/slotted screw heads
- 30.3 cu. in. capacity
- Includes 8 in. #12 solid copper ground pigtail
- Acceptable for use in 2-hour fire rated walls

General

Bracket Type	M, for Metal or Wood Studs
Catalog Number	232MSCM
Color	Gray
Drawn or Welded	Welded
Fire Resistance	Yes
Knockouts	1/2 in;1/2 - 3/4 in Combination (TKO)
Material	Steel
Number of Gang(s)	2-Gang
Type	Box
UPC	050169922323

Dimensions

Actual Depth	2.64 in
Cubic Capacity	30.3 cu.in
Depth	2.125 in
Height	4.17 in
Raised Ground	Yes
Weight	1.212 lb
Width	5.86 in

Certifications And Compliance

Certified Listed	UL Listed
------------------	-----------

Logistics

Carton Quantity	25
Pallet Quantity	1375

Product Assets

[3D Models - 232MSCM-3D](#)
[Brochures - STAB-iT® Electrical Boxes](#)
[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - UL COC - E195978-5](#)
[Certifications - UL COC - E195978- 2](#)
[Installation Manuals - 119030_RA-356 Instr for web](#)
[Product Logo - STAB-IT](#)
[Sales Drawings - 232MSCM Customer Drawing](#)
[SDS - HCC SDS](#)
[Sell Sheets - RACO® STAB-IT](#)
[Terms and Conditions - HCC Terms & Conditions](#)
[Video - RACO: STAB-IT® with Cable Management](#)
[Video - RACO: STAB-IT® vs competition](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-232MSCM-SPEC-EN | REV 6/2024