




4 in. Square Box, Welded with (2) STAB-IT® Connectors, 2-1/8 in. Deep, 600V, 8 in. #12 Solid Copper Pigtail, UBS, M Bracket

By Raco
Catalog # 248MS

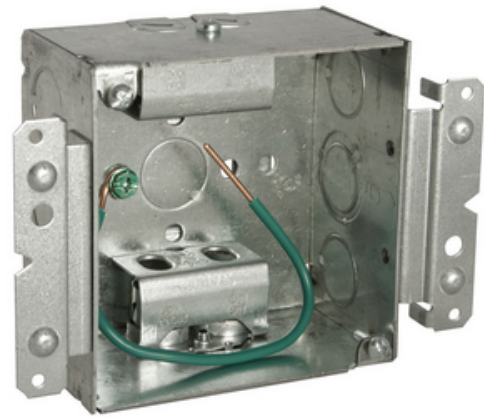

4 in. Square Box, Welded with (2) STAB-IT® Connectors, 2-1/8 in. Deep, 600V, 8 in. #12 Solid Copper Pigtail, UBS, M Bracket

Features

- Welded steel construction with "UBS" support with present bend points to work with wall thickness 2-1/2 to 6 in. and "M" brackets on both sides of box
- 4 in. square x 2-1/8 in. deep
- TKO® Knockouts allow for design and installation flexibility
- Supplied with five 1/2 in. and two 1/2-3/4 in. TKO® knockouts
- Combination Phillips/slotted screw heads
- 30.3 cu. in. capacity
- Includes 8 in. #12 solid copper ground pigtail
- Acceptable for use in 2-hour fire rated walls

General

Application	RACO® STAB-IT boxes are great for any job where flexible armored cable is being used RACO® Boxes are installed in walls or ceilings for lighting fixtures, switches or receptacles
Bracket Setback	0.375
Bracket Type	M, for Metal or Wood Studs
Catalog Number	248MS
Color	Gray
Drawn or Welded	Welded
Fire Resistance	Yes
Knockouts	1/2 in.; 1/2 - 3/4 in Combination (TKO)
Material	Steel
Number of Gang(s)	2-Gang
Type	Box
UPC	050169500798

Dimensions

Actual Depth	2.64 in
Cubic Capacity	30.3 cu.in
Depth	2.125 in
Height	4.21 in
Raised Ground	Yes
Weight	1.183 lb
Width	5.86 in

Electrical Ratings

Voltage Rating	600 V
----------------	-------

Certifications And Compliance

Certified Listed	UL Listed
------------------	-----------

Logistics

Carton Quantity	25
Pallet Quantity	1375

Product Assets

- [3D Models - 248MS-CN3D](#)
- [Brochures - STAB-iT® Electrical Boxes](#)
- [Catalogs - RACO / TayMac / Bell Full Catalog](#)
- [Product Logo - STAB-IT](#)
- [Sales Drawings - 248MS Customer Drawing](#)
- [SDS - HCC SDS](#)
- [Sell Sheets - RACO® STAB-IT](#)
- [Terms and Conditions - HCC Terms & Conditions](#)
- [Video - RACO: STAB-IT® with Cable Management](#)
- [Video - RACO: STAB-IT® vs competition](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-248MS-SPEC-EN | REV 6/2024