




4 in. Square Box, Welded, 2-1/8 in. Deep, Nine 1/2 in. KO's and Five TKO's, B Bracket

By Raco
Catalog # 251

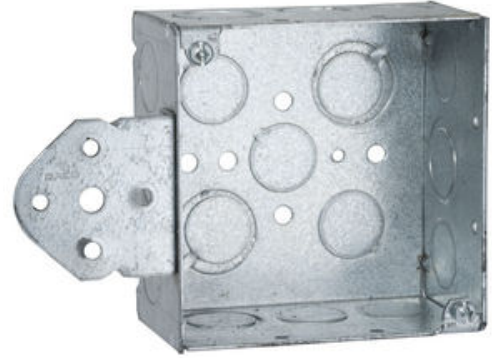

4 in. Square Box, Welded, 2-1/8 in. Deep, Nine 1/2 in. KO's and Five TKO's, B Bracket

Features

- B style bracket, flush
- Combination screw heads allow quick installation
- Welded construction
- Nine 1/2 in. knockouts and Five TKO knockouts
- UL Listed
- 30.3 cu. in. capacity
- Acceptable in 2-hour fire rated walls

General

Bracket Type	B, for Wood Studs
Color	Gray
Drawn or Welded	Welded
EU RoHS Indicator	Contact Manufacturer
Fire Resistance	Yes
Knockouts	1/2 in.; 1/2 - 3/4 in Combination (TKO)
Material	Steel
Number of Gang(s)	2-Gang
Type	Box
UPC	050169002513
Wiring System	Conduit

Dimensions

Actual Depth	2.188 in
Cubic Capacity	30.3 cu.in
Depth	2.125 in
Height	4 in
Raised Ground	No
Weight	0.944 lb
Width	6 in

Certifications And Compliance

Certified Listed	cULus Listed
------------------	--------------

Logistics

Carton Quantity	25
Packaging Type	No Packaging
Pallet Quantity	1750

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - UL COC - E195978- 2](#)
[Certifications - LEED Statement](#)
[Certifications - NEMA OS1](#)
[Certifications - UL COC - E195978-5](#)
[Sales Drawings - 251](#)
[Sales Drawings - RACO-welded-steel-box-infographic](#)
[SDS - HCC SDS](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-251-SPEC-EN | REV 6/2024