



Stab-iT® II 4-11/16" Electrical Box

By Raco
Catalog # 252MSCMHF

4-11/16 in. Square Box, Welded with STAB-IT® Connector, 2-1/8 in. Deep, 600V, Raised Ground, 8 in. #12 Solid Copper Pigtail, Heavy Duty Universal Bracket Support, M Bracket, Cable Management Clip

Features


- Designed for quick installation of flex, MC, MCI, MCI-A, MC-PCS, AC, and HCF cable
- Accepts cable sizes from 14/2 up to 10/3 for most cable types
- 3 TIMES FASTER than traditional connectors
- 4-11/16 in. sq. boxes are 2-1/8 in. deep and includes 1 STAB-IT® II connector
- Each STAB-IT® II connector accomodates three cables
- Includes built-in cable management clip, offering first means of support
- UL Listed for use without a plastic bushing (except for AC cable)
- Pre-installed 8 in. solid #12 pigtail for faster installation
- Suitable for use without a bonding jumper in circuits up to 600 volts
- Improved design allows each cable to easily be removed, allows connector to be reused
- Designed in USA

Application

Commercial

General

Bracket Type	M, for Metal or Wood Studs
Catalog Number	252MSCMHF
Color	Gray
Drawn or Welded	Welded
Fire Resistance	Yes

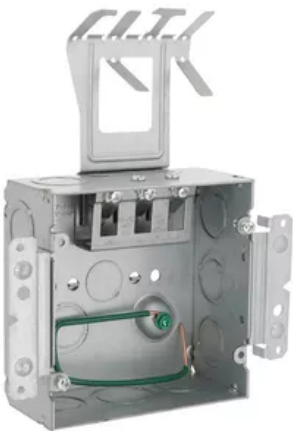

Knockouts - Bottom	(1) 1/2", (1) 1.2"-3/4" TKO
Knockouts - Side	(9) 1/2" - 3/4" TKO, (1) 3/4-1" TKO
Number of Gang(s)	2-Gang
UPC	0501699992913

Dimensions

Raised Ground	Yes
---------------	-----

Certifications And Compliance

Buy America(n) Qualified	Contact Manufacturer
Certified Listed	UL Listed

Logistics

Carton Quantity	25
Pallet Quantity	800

Product Assets

[Brochures - STAB-iT® Electrical Boxes](#)
[Catalogs - Steel Boxes, Covers and Accessories](#)
[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - UL COC - E195978- 2](#)
[Installation Manuals - 119030_RA-356 Instr for web](#)
[Sales Drawings - 252MSCMHF Customer Drawing](#)
[Specifications - 252MSCMHF](#)
[Video - RACO: STAB-IT® II Boxes](#)
[Video - RACO: STAB-IT® with Cable Management](#)



A Hubbell brand