




4-11/16 in. Square Box, Welded, 2-1/8 in. Deep with 16 Knockouts, Raised, 8 in. #12 Stranded Copper Pigtail, UBS, H Bracket

By Raco
Catalog # 257H

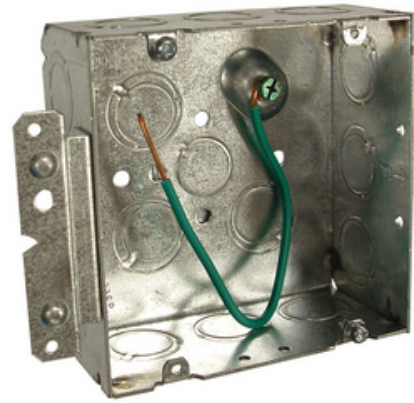

4-11/16 in. Square Box, Welded, 2-1/8 in. Deep with One 1/2 in. KO & Fifteen TKO's, Raised, 8 in. #12 Stranded Copper Pigtail, UBS, H Bracket

Features

- Reference the Box Selection section in the front of this catalog for complete description of bracket types and features
- Combination screw heads provide for faster installation
- TKO knockouts allow for design and installation flexibility
- UBS Support - Welded to box, preset bend points to work with wall thickness 2-1/2 in. to 6 in
- Welded steel construction
- 4-11/16 in. square x 2-1/8 in. deep
- Supplied with one (1) 1/2 in. and fifteen (15) 1/2 and 3/4 in. TKO knockouts
- Combination Phillips/slotted screw heads
- 8 in. #12 stranded pigtail

General

Bracket Setback	0.375
Bracket Type	H, for Metal or Wood Studs
Color	Gray
Drawn or Welded	Welded
EU RoHS Indicator	Contact Manufacturer
Knockouts	1/2 in.; 1/2 - 3/4 in Combination (TKO)
Material	Steel
Number of Gang(s)	2-Gang
Type	Box
UPC	050169500064
Wiring System	Conduit

Dimensions

Actual Depth	2.75 in
Cubic Capacity	42 cu.in
Depth	2.125 in
Height	4.688 in
Raised Ground	Yes
Weight	1.2 lb
Width	5.603 in

Certifications And Compliance

Certified Listed	UL Listed
------------------	-----------

Logistics

Carton Quantity	20
Packaging Type	No Packaging
Pallet Quantity	1080

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - UL COC - E195978-5](#)
[Certifications - UL COC - E195978- 2](#)
[Certifications - LEED Statement](#)
[Certifications - NEMA OS1](#)
[Sales Drawings - 257H](#)
[Sales Drawings - RACO-welded-steel-box-infographic](#)
[SDS - HCC SDS](#)
[Sell Sheets - H&M Series](#)
[Terms and Conditions - HCC Terms & Conditions](#)
[Video - RACO: H&M Series Installation](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-257H-SPEC-EN | REV 6/2024