




## 4-11/16 in. Square Box, Welded, 2-1/8 in. Deep w/ 16 Knockouts, 8 in. #12 Stranded Copper Pigtail, UBS, M Bracket

By Raco  
Catalog # 257M

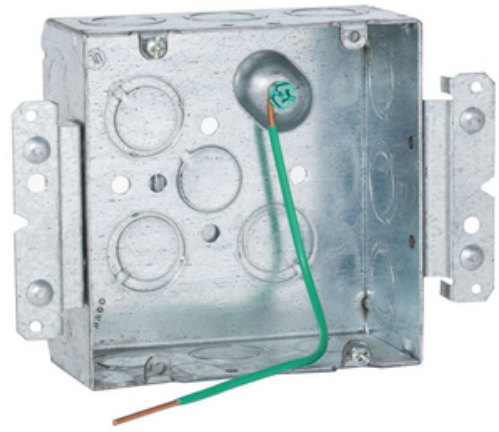

4-11/16 in. Square Box, Welded, 2-1/8 in. Deep with One 1/2 in. KO & Fifteen TKO's, Raised, 8 in. #12 Stranded Copper Pigtail, UBS, M Bracket

### Features

- Reference the Box Selection section in the front of this catalog for complete description of bracket types and features
- Combination screw heads provide for faster installation
- TKO knockouts allow for design and installation flexibility
- UBS Support - Welded to box, preset bend points to work with wall thickness 2-1/2 in. to 6 in
- Welded steel construction
- 4-11/16 in. square x 2-1/8 in. deep
- Supplied with one (1) 1/2 in. and fifteen (15) 1/2 and 3/4 in. TKO knockouts
- Combination Phillips/slotted screw heads
- 8 in. #12 stranded pigtail

### General

Bracket Setback	0.375
Bracket Type	M, for Metal or Wood Studs
Color	Gray
Drawn or Welded	Welded
EU RoHS Indicator	Contact Manufacturer
Knockouts	1/2 in.; 1/2 - 3/4 in Combination (TKO)
Material	Steel
Number of Gang(s)	2-Gang
Type	Box
UPC	050169500071
Wiring System	Conduit

### Dimensions

Actual Depth	2.75 in
Cubic Capacity	42 cu.in
Depth	2.125 in
Height	4.688 in
Raised Ground	Yes
Weight	1.23 lb
Width	6.545 in

### Certifications And Compliance

Certified Listed	UL Listed
------------------	-----------

### Logistics

Carton Quantity	20
Packaging Type	No Packaging
Pallet Quantity	1080

### Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)  
[Certifications - UL COC - E195978-5](#)  
[Certifications - UL COC - E195978- 2](#)  
[Certifications - LEED Statement](#)  
[Certifications - NEMA OS1](#)  
[Sales Drawings - 257M](#)  
[Sales Drawings - RACO-welded-steel-box-infographic](#)  
[SDS - HCC SDS](#)  
[Sell Sheets - H&M Series](#)  
[Terms and Conditions - HCC Terms & Conditions](#)  
[Video - RACO: H&M Series Installation](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
RACO-257M-SPEC-EN | REV 6/2024