




4-11/16 in. Square Box, Welded, 2-1/8 in. Deep with Twelve Knockouts, Raised, 10 in. #12 Stranded Copper Pigtail

By Raco
Catalog # 258SM

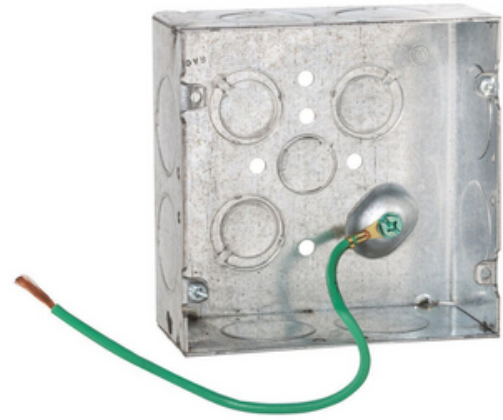

4-11/16 in. Square Box, Welded, 2-1/8 in. Deep with One 1/2 in., Eight 1 in., and Three TKO's, Raised, 10 in. #12 Stranded Copper Pigtail

Features

- Combination screw heads provide for faster installation
- TKO knockouts allow for design and installation flexibility

General

Bracket Type	No Bracket
Catalog Number	258SM
Drawn or Welded	Welded
EU RoHS Indicator	Contact Manufacturer
Knockouts	1/2 in;1 in;1/2 - 3/4 in Combination (TKO)
Material	Steel
Type	Box
UPC	050169982587
Wiring System	Conduit

Dimensions

Actual Depth	2.188 in
Cubic Capacity	42 cu.in
Depth	2.125 in
Height	4.688 in
Raised Ground	Yes
Weight	1.157 lb
Width	4.688 in

Certifications And Compliance

Certified Listed UL Listed

Logistics

Carton Quantity	25
Packaging Type	No Packaging
Pallet Quantity	1500

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - UL COC - E195978- 2](#)
[Certifications - LEED Statement](#)
[Certifications - NEMA OS1](#)
[Certifications - UL COC - E195978-5](#)
[Sales Drawings - 258SM](#)
[Sales Drawings - RACO-welded-steel-box-infographic](#)
[SDS - HCC SDS](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-258SM-SPEC-EN | REV 6/2024