




4 in. x 4 in. Switch Box, Nongangable, 1 in. Deep, Two 1/2 in KO's & NMSC Clamps

By Raco
Catalog # 418

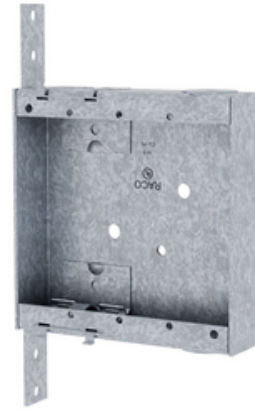

4 in. x 4 in. Switch Box, Nongangable, 1 in. Deep, Two 1/2 in KO's
& NMSC Clamps

Features

- 4 in. x 4 in., 1 in. deep
- Shallow switch box is made for use with furring strips and 1/4 in. paneling
- RACO® "D" bracket is pre-scored and can be broken off if needed
- Q clamps provided for non-metallic sheathed cable (NMSC)
- Accepts 4 in. square mudring or flat cover
- Supplied with two 1/2 in. knockouts
- 14.8 cu. in. capacity
- Non-gangable
- Acceptable for use in 2-hour fire rated walls

General

Bracket Setback	0.25
Bracket Type	D, for Metal or Wood Studs
Color	Gray
EU RoHS Indicator	Contact Manufacturer
Ends Cable	4
Fire Resistance	Yes
Gangable	No
Knockouts	1/2 in
Material	Steel
Number of Gang(s)	2-Gang
Plaster Ears	No
Type	Switch Box
	Box
UPC	050169004180
Wiring System	Nonmetallic Sheathed Cable

Dimensions

Actual Depth	1.156 in
Cubic Capacity	14.8 cu.in
Depth	1 in
Height	6.75 in
Weight	0.686 lb
Width	4 in

Certifications And Compliance

Certified Listed UL Listed

Logistics

Carton Quantity	25
Packaging Type	No Packaging
Pallet Quantity	2500

Product Assets

[3D Product View - RACO_418](#)
[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - LEED Statement](#)
[Certifications - NEMA OS1](#)
[Sales Drawings - 418](#)
[SDS - HCC SDS](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-418-SPEC-EN | REV 6/2024