



3 in. x 2 in. Switch Box, Gangable, 2-1/2 in. Deep, Eight 1/2 in. KO's, B Bracket

By Raco
Catalog # 502

3 in. x 2 in. Switch Box, Gangable, 2-1/2 in. Deep, Eight 1/2 in. KO's, B Bracket

Features

- 3 in. x 2 in., 2-1/2 in. deep
- Includes B bracket for mounting to metal or wood studs with 5/8 in. set back
- Gangable switch boxes offer the option of constructing a box to hold two or more devices
- With proper fitting can be used for conduit, NMSC, armored, metal clad, flex cable
- Supplied with eight 1/2 in. knockouts
- 12.5 cu. in. capacity
- Acceptable for use in 2-hour fire rated walls

General


Bracket Type	B, for Wood Studs
Catalog Number	502
Color	Gray
EU RoHS Indicator	Contact Manufacturer
Fire Resistance	Yes
Gangable	Yes
Knockouts	1/2 in
Material	Steel
Number of Gang(s)	1-Gang
Plaster Ears	No
Type	Switch Box
	Box
UPC	050169005026
Wiring System	Conduit

Dimensions

Cubic Capacity	12.5 cu.in
Depth	2.5 in
Height	3.375 in
Weight	0.571 lb
Width	3.969 in

Certifications And Compliance

Certified Listed	UL Listed
------------------	-----------

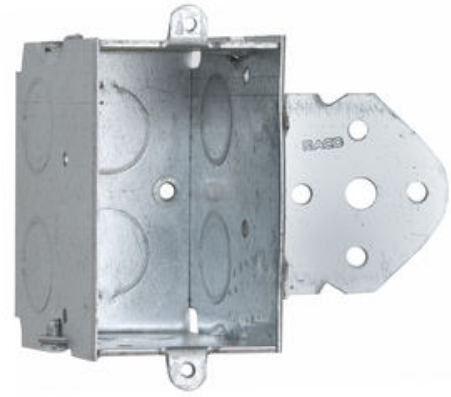

Logistics

Carton Quantity	10
Packaging Type	No Packaging
Pallet Quantity	1980

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - UL COC - E195978-18](#)
[SDS - HCC SDS](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-502-SPEC-EN | REV 6/2024