




3 in. x 2 in. Switch Box, 2-1/2 in. Deep, Two 1/2 in. KO's, Plaster Ears, Old Work, 3/4 in. Sheet Rock Maximum

By Raco
Catalog # 508

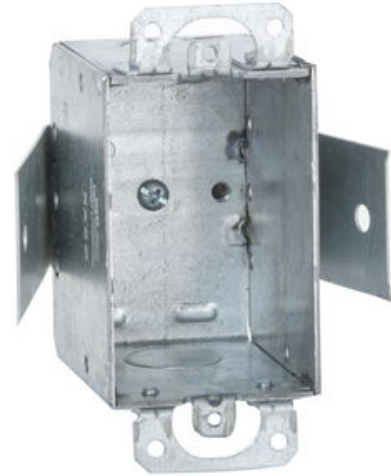

3 in. x 2 in. Switch Box, 2-1/2 in. Deep, Two 1/2 in. KO's, Plaster Ears, Old Work, 3/4 in. Sheet Rock Maximum

Features

- 3 in. x 2 in., 2-1/2 in. deep
- Non-gangable
- Supplied with two 1/2 in. knockouts
- Includes plaster ears and saddle bracket for "cut-in" or "old work" applications
- 12.5 cu. in. capacity
- Acceptable for use in 2-hour fire rated walls

General

Bracket Type	No Bracket
Color	Gray
EU RoHS Indicator	Contact Manufacturer
Fire Resistance	Yes
Gangable	Yes
Knockouts	1/2 in
Material	Steel
Number of Gang(s)	1-Gang
Plaster Ears	Yes
Type	Switch Box
	Box
UPC	050169005088
Wiring System	Conduit

Dimensions

Cubic Capacity	12.5 cu.in
Depth	2.5 in
Height	4.219 in
Weight	0.498 lb
Width	3 in

Certifications And Compliance

Certified Listed	cULus Listed
------------------	--------------

Logistics

Carton Quantity	20
Packaging Type	No Packaging
Pallet Quantity	1820

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - LEED Statement](#)
[Certifications - NEMA OS1](#)
[SDS - HCC SDS](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-508-SPEC-EN | REV 6/2024