




## 3 in. x 2 in. Switch Box, Gangable, 2-1/2 in. Deep, Three 1/2 in. KO & AC/MC/Flex Clamps, LB Bracket

By Raco  
Catalog # 522

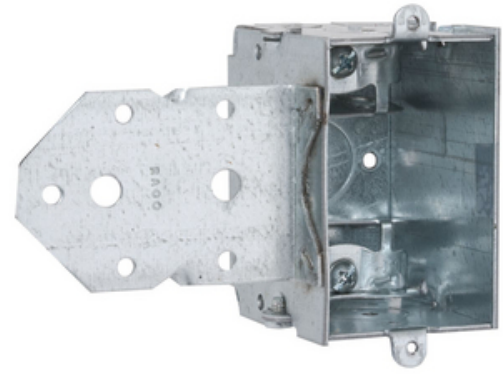

3 in. x 2 in. Switch Box, Gangable, 2-1/2 in. Deep, Three 1/2 in. KO & AC/MC/Flex Clamps, LB Bracket

### Features

- 3 in. x 2 in., 2-1/2 in. deep
- Includes "long B" bracket for mounting to metal or wood studs with 5/8 in. set back
- BX clamps provided for steel and alum armored cable, MCI cable, MCI-A cable, and flexible conduit
- Gangable switch boxes offer the option of constructing a box to hold two or more devices
- Supplied with three 1/2 in. knockouts
- 12.5 cu. in. capacity
- Acceptable for use in 2-hour fire rated walls

### General

Bracket Setback	0.625
Bracket Type	LB, for Wood Studs
Catalog Number	522
Color	Gray
EU RoHS Indicator	Contact Manufacturer
Ends Cable	4
Fire Resistance	Yes
Gangable	Yes
Knockouts	1/2 in
Material	Steel
Number of Gang(s)	1-Gang
Plaster Ears	No
Type	Switch Box
	Box
UPC	050169005224
Wiring System	Armored Cable/Metal Clad/MCI-A/Flex

### Dimensions

Cubic Capacity	12.5 cu.in
Depth	2.5 in
Height	3.375 in
Weight	0.69 lb
Width	5.047 in

### Electrical Ratings

Power Distribution Features      Fire Rated

### Certifications And Compliance

Certified Listed      UL Listed

### Logistics

Carton Quantity      25  
Packaging Type      No Packaging  
Pallet Quantity      2275

### Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)  
[SDS - HCC SDS](#)  
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
RACO-522-SPEC-EN | REV 6/2024