




3 in. x 2 in. Switch Box, Gangable, 2-1/2 in. Deep, Three 1/2 in. KO & AC/MC/Flex Clamps, TS Bracket

By Raco
Catalog # 524

3 in. x 2 in. Switch Box, Gangable, 2-1/2 in. Deep, Three 1/2 in. KO & AC/MC/Flex Clamps, TS Bracket

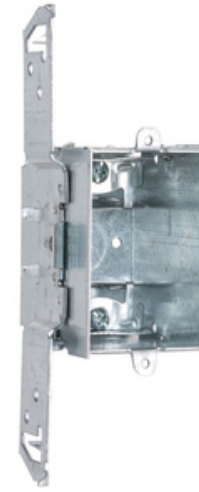

Features

- 3 in. x 2 in., 2-1/2 in. deep
- Includes TS side-mount bracket with gauging tabs and recessed nailing spurs
- BX clamps provided for steel & alum armored cable, MCI cable, MCI-A cable and flexible conduit
- Gangable switch boxes offer the option of constructing a box to hold two or more devices
- Supplied with three 1/2 in. knockouts
- 12.5 cu. in. capacity
- Acceptable for use in 2-hour fire rated walls

General

Bracket Setback	0.5
Bracket Type	TS, for Metal or Wood Studs
Catalog Number	524
EU RoHS Indicator	Contact Manufacturer
Ends Cable	4
Fire Resistance	Yes
Gangable	Yes
Knockouts	1/2 in
Material	Steel
Plaster Ears	No
Type	Switch Box
	Box
UPC	050169905241
Wiring System	Armored Cable/Metal Clad/MCI-A/Flex

Dimensions

Cubic Capacity	12.5 cu.in
Depth	2.5 in
Height	7 in
Weight	0.707 lb
Width	2.203 in

Certifications And Compliance

Certified Listed UL Listed

Logistics

Carton Quantity	50
Packaging Type	No Packaging
Pallet Quantity	2100

Product Assets

- [3D Product View - RACO_8524](#)
- [Catalogs - RACO / TayMac / Bell Full Catalog](#)
- [Certifications - UL COC - E195978-21](#)
- [Sales Drawings - 524 Customer Drawing](#)
- [SDS - HCC SDS](#)
- [Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-524-SPEC-EN | REV 6/2024