




## 3 in. x 2 in. Switch Box, 2-1/2 in. Deep, AC/MC/Flex Clamps, Plaster Ears, Old Work, 3/4 in. Sheet Rock Maximum

By Raco  
Catalog # 526

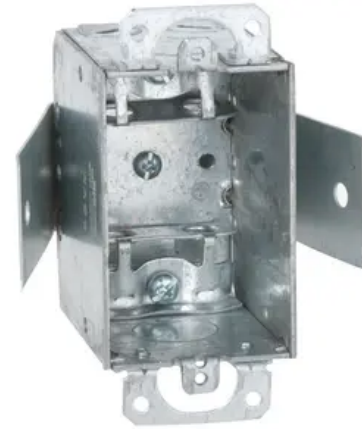

3 in. x 2 in. Switch Box, 2-1/2 in. Deep, AC/MC/Flex Clamps, Plaster Ears, Old Work, 3/4 in. Sheet Rock Maximum

### Features

- 3 in. x 2 in., 2-1/2 in. deep
- BX clamps provided for steel & alum armored cable, MCI cable, MCI-A cable, and flexible conduit
- Includes plaster ears and saddle bracket for "cut-in" or "old work" applications
- Non-gangable
- 12.5 cu. in. capacity
- Acceptable for use in 2-hour fire rated walls

### General

Bracket Type	No Bracket
Catalog Number	526
Color	Gray
EU RoHS Indicator	Contact Manufacturer
Ends Cable	4
Fire Resistance	Yes
Gangable	Yes
Knockouts	1/2 in
Material	Steel
Number of Gang(s)	1-Gang
Plaster Ears	Yes
Type	<ul style="list-style-type: none"><li>• Switch Box</li><li>• Box</li></ul>
UPC	050169005262
Wiring System	Armored Cable/Metal Clad/MCI-A/Flex

### Dimensions

Cubic Capacity	12.5 cu.in
Depth	2.5 in
Height	4.219 in
Weight	0.65 lb
Width	3.406 in

### Electrical Ratings

Power Distribution Features	Fire Rated
-----------------------------	------------

### Certifications And Compliance

Buy American Compliant	Contact Manufacturer
Certified Listed	UL Listed

### Logistics

Carton Quantity	20
Packaging Type	No Packaging

### Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)  
[Certifications - LEED Statement](#)  
[Certifications - NEMA OS1](#)  
[Sales Drawings - 526 Customer Drawing](#)  
[SDS - HCC SDS](#)  
[Specifications - 526](#)  
[Terms and Conditions - HCC Terms & Conditions](#)