




## 3 in. x 2 in. Switch Box, Gangable, 2-1/2 in. Deep, Three 1/2 in. KO's & NMSC Clamps, LB Bracket

By Raco  
Catalog # 529

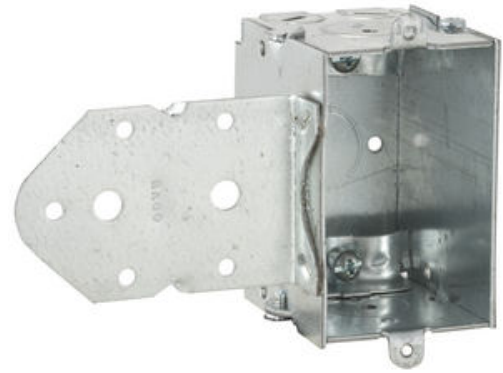

3 in. x 2 in. Switch Box, Gangable, 2-1/2 in. Deep, Three 1/2 in. KO's & NMSC Clamps, LB Bracket

### Features

- 3 in. x 2 in., 2-1/2 in. deep
- Gangable switch boxes offer the option of constructing a box to hold two or more devices
- Includes "LB" bracket to face mount on front edge of wood stud, 5/8 in. offset to clear narrow door molding
- L clamps provided for Nonmetallic Sheathed Cable (NMSC)
- Supplied with three 1/2 in. knockouts
- 12.5 cubic in. capacity
- Acceptable for use in 2-hour fire rated walls

### General

Bracket Setback	0.625
Bracket Type	LB, for Wood Studs
Color	Gray
EU RoHS Indicator	Contact Manufacturer
Ends Cable	4
Fire Resistance	Yes
Gangable	Yes
Knockouts	1/2 in
Material	Steel
Number of Gang(s)	1-Gang
Plaster Ears	No
Type	Switch Box
	Box
UPC	050169005293
Wiring System	Nonmetallic Sheathed Cable

### Dimensions

Cubic Capacity	12.5 cu.in
Depth	2.5 in
Height	4.219 in
Weight	0.685 lb
Width	5.594 in

### Electrical Ratings

Power Distribution Features	Fire Rated
-----------------------------	------------

### Certifications And Compliance

Certified Listed	UL Listed
------------------	-----------

### Logistics

Carton Quantity	20
Packaging Type	No Packaging
Pallet Quantity	2160

### Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)  
[Certifications - UL COC - E195978-8](#)  
[Certifications - UL COC - E195978- 8](#)  
[SDS - HCC SDS](#)  
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
RACO-529-SPEC-EN | REV 6/2024