




## 3 in. x 2 in. Switch Box, Gangable, 2-1/2 in. Deep, Two 1/2 in. KO's & NMSC Clamps, Plaster Ears, Old Work

By Raco  
Catalog # 545

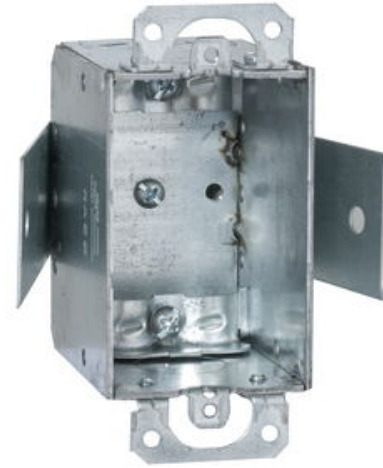

3 in. x 2 in. Switch Box, Gangable, 2-1/2 in. Deep, Two 1/2 in. KO's & NMSC Clamps, Plaster Ears, Old Work, 3/4 in. Sheet Rock Maximum

### Features

- 3 in. x 2 in., 2-1/2 in. deep
- Gangable switch boxes offer the option of constructing a box to hold two or more devices
- Cable clamps suitable for use with nonmetallic sheathed cable
- Plaster ears allow a box to be used in "old work" applications
- Supplied with two 1/2 in. knockouts
- 12.5 cu. in. capacity
- Acceptable for use in 2-hour fire rated walls

### General

Bracket Type	No Bracket
Catalog Number	545
Color	Gray
EU RoHS Indicator	Contact Manufacturer
Ends Cable	4
Fire Resistance	Yes
Gangable	Yes
Knockouts	1/2 in
Material	Steel
Number of Gang(s)	1-Gang
Plaster Ears	Yes
Type	Switch Box
	Box
UPC	050169005453
Wiring System	Nonmetallic Sheathed Cable

### Dimensions

Actual Depth	2.5 in
Cubic Capacity	12.5 cu.in
Depth	2.5 in
Height	4.219 in
Weight	0.65 lb
Width	3.406 in

### Electrical Ratings

Power Distribution Features      Fire Rated

### Certifications And Compliance

Certified Listed      UL Listed

### Logistics

Carton Quantity      20  
Packaging Type      No Packaging  
Pallet Quantity      1820

### Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)  
[Certifications - LEED Statement](#)  
[Certifications - NEMA OS1](#)  
[Sales Drawings - 545 Customer Drawing](#)  
[SDS - HCC SDS](#)  
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
RACO-545-SPEC-EN | REV 6/2024