




3 in x 2 in. Switch Box, Gangable, 3-1/2 in. Deep, Three 1/2 in. KO's & AC/MC/Flex Clamps, Plaster Ears

By Raco
Catalog # 600

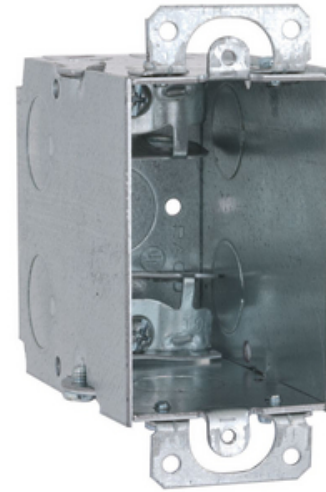

3 in x 2 in. Switch Box, Gangable, 3-1/2 in. Deep, Three 1/2 in. KO's & AC/MC/Flex Clamps, Plaster Ears

Features

- 3 in. x 2 in., 3-1/2 in. deep
- Gangable switch boxes offer the option of constructing a box to hold two or more devices
- Plaster ears allow a box to be used in "old work" applications
- Cable clamps suitable for use with steel and alum armored cable, MCI cable, MCI-A cable, and flexible conduit
- Supplied with seven 1/2 in. knockouts
- 18.0 cu. in. capacity
- Acceptable for use in 2-hour fire rated walls

General

Bracket Type	No Bracket
Catalog Number	600
Color	Gray
EU RoHS Indicator	Contact Manufacturer
Ends Cable	4
Fire Resistance	Yes
Gangable	Yes
Knockouts	1/2 in
Material	Steel
Number of Gang(s)	1-Gang
Plaster Ears	Yes
Type	Switch Box
	Box
UPC	050169006009
Wiring System	Armored Cable/Metal Clad/MCI-A/Flex

Dimensions

Cubic Capacity	18 cu.in
Depth	3.5 in
Height	4.219 in
Weight	0.796 lb
Width	2 in

Certifications And Compliance

Certified Listed UL Listed

Logistics

Carton Quantity	25
Packaging Type	No Packaging
Pallet Quantity	2000

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - UL COC - E195978-18](#)
[SDS - HCC SDS](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-600-SPEC-EN | REV 6/2024