




3 in x 2 in. Switch Box, Gangable, 3-1/2 in. Deep, Seven 1/2 in. KO's & NMSC Clamps, B Bracket

By Raco
Catalog # 603

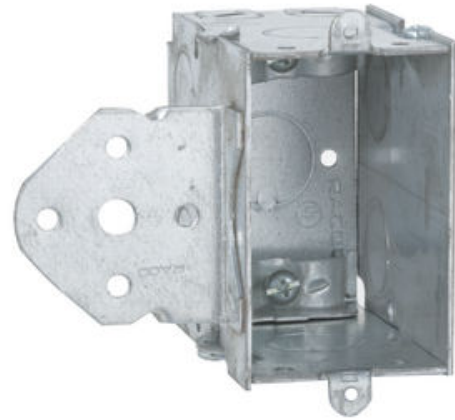

3 in x 2 in. Switch Box, Gangable, 3-1/2 in. Deep, Seven 1/2 in. KO's & NMSC Clamps, B Bracket

Features

- 3 in. x 2 in., 3-1/2 in. deep
- Gangable switch boxes offer the option of constructing a box to hold two or more devices
- Includes "B" bracket which face mounts on front edge of wood stud
- Cable clamps suitable for use with nonmetallic sheathed cable
- Supplied with seven 1/2 in. knockouts
- 18.0 cu. in. capacity
- Acceptable for use in 2-hour fire rated walls

General

Bracket Setback	0.25
Bracket Type	B, for Wood Studs
Catalog Number	603
Color	Gray
EU RoHS Indicator	Contact Manufacturer
Ends Cable	4
Fire Resistance	Yes
Gangable	Yes
Knockouts	1/2 in
Material	Steel
Number of Gang(s)	1-Gang
Plaster Ears	No
Type	Switch Box
	Box
UPC	050169006030
Wiring System	Nonmetallic Sheathed Cable

Dimensions

Cubic Capacity	18 cu.in
Depth	3.5 in
Height	3.375 in
Weight	0.834 lb
Width	4.203 in

Certifications And Compliance

Certified Listed UL Listed

Logistics

Carton Quantity	25
Packaging Type	No Packaging
Pallet Quantity	2000

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - UL COC - E195978-18](#)
[Sales Drawings - 603 Customer Drawing](#)
[SDS - HCC SDS](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-603-SPEC-EN | REV 6/2024