


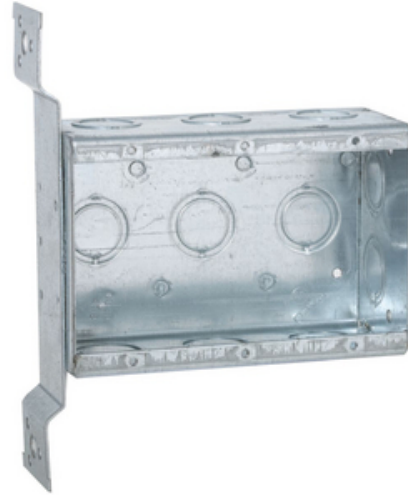

3-Gang Switch Box, Welded, 2-1/2 in Deep, Eleven 1/2 & Eleven 3/4 in. KO's

By Raco
Catalog # 686

3-Gang Switch Box, Welded, 2-1/2 in Deep, Eleven 1/2 & Eleven 3/4 in. KO's



Features

- Reference the Box Selection section in the front of this catalog for complete description of bracket types and features.
- Supplied with eleven (11) 1/2 and 3/4 in. concentric knockouts
- Welded steel construction with "FM" bracket - 1/2 in. set back
- Standard device spacing with tapped 6-32 holes for devices
- Uses Raco 971 voltage partition
- 47.8 cu. in. capacity

General

Bracket Setback	0.5
Bracket Type	FM, for Metal or Wood Studs
Color	Gray
Drawn or Welded	Welded
EU RoHS Indicator	Contact Manufacturer
Knockouts	1/2 in;3/4 in
Material	Steel
Number of Gang(s)	3-Gang
Type	<ul style="list-style-type: none">• Box• Large Capacity
UPC	050169006863
Wiring System	Conduit

Dimensions

Cubic Capacity	47.8 cu.in
Depth	2.5 in
Height	7.625 in
Weight	1.379 lb
Width	6.97 in

Certifications And Compliance

Certified Listed	UL Listed
------------------	-----------

Logistics

Carton Quantity	10
Packaging Type	No Packaging
Pallet Quantity	600

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - UL COC - E195978 1.51](#)
[Sales Drawings - RACO-welded-steel-box-infographic](#)
[SDS - HCC_SDS](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
RACO-686-SPEC-EN | REV 6/2024