




4 in. Square Cover, Universal Exposed Work, 2-Device, 6-in-1 Plates

By Raco
Catalog # 809U

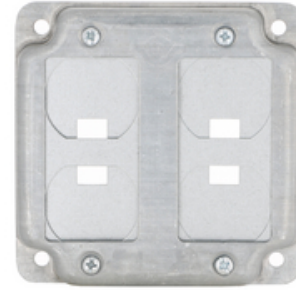

4 in. Square Cover, Universal Exposed Work, 2-Device, 6-in-1 Plates

Features

- RACO® exposed work covers include required hardware for mounting the receptacle(s)
- RACO® exposed work covers meet the requirements of the 2014 NEC Article 250.146(A). No bonding jumper is required for covers with: (1) Crushed corners
- Hardware and cover are packed in a poly-bag with printed catalog number, compliances and installation instructions
- Accommodates 1-1/4 in. drywall thickness
- Pre-galvanized steel construction

General

Catalog Number	809U
EU RoHS Indicator	Contact Manufacturer
Material	809U
Paintable/Stainable	Yes
Type	Exposed Cover
UPC	050169978092

Dimensions

Cubic Capacity	6.5 cu.in
Dimensions	0.563 in x 4.125 in x 4.125 in
Height	4.125 in
Length	0.563 in
Weight	0.4 lb
Width	4.125 in

Certifications And Compliance

Certified Listed	UL Listed
------------------	-----------

Logistics

Carton Quantity	10
Minimum Pack Quantity	10
Packaging Type	Polybag
Pallet Quantity	3960

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Installation Manuals - RACO Crushed Corners Covers Instruction Sheet](#)
[Sales Drawings - 809U Customer Drawing](#)
[SDS - HCC SDS](#)
[Sell Sheets - Exposed Work Covers](#)
[Sell Sheets - Service Truck Solutions](#)
[Sell Sheets - Universal Exposed Work Covers](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-809U-SPEC-EN | REV 6/2024