



4 in. Square Box, Welded, 1-1/2 in. Deep with NMSC Clamps, Five 1/2 in. KO's and Two TKO's

By Raco
Catalog # 8211

4 in. Square Box, Welded, 1-1/2 in. Deep with NMSC Clamps, Five 1/2 in. KO's and Two TKO's

Features

- Welded steel construction with nonmetallic sheathed cable clamps
- 4 in. square x 1-1/2 in. deep
- TKO® Knockouts allow for design and installation flexibility
- Supplied with five 1/2 in. and two 1/2-3/4 in. TKO® knockouts
- Combination Phillips/slotted screw heads
- 21.0 cu. in. capacity
- Acceptable for use in 2-hour fire rated walls

General


Bracket Type	No Bracket
Drawn or Welded	Welded
EU RoHS Indicator	Contact Manufacturer
Fire Resistance	Yes
Knockouts	1/2 in.; 1/2 - 3/4 in Combination (TKO)
Material	Steel
Type	Box
UPC	050169002117
Wiring System	Nonmetallic Sheathed Cable

Dimensions

Actual Depth	2 in
Cubic Capacity	21 cu.in
Depth	1.5 in
Height	4 in
Raised Ground	No
Weight	0.771 lb
Width	4 in

Certifications And Compliance

Certified Listed	UL Listed
------------------	-----------

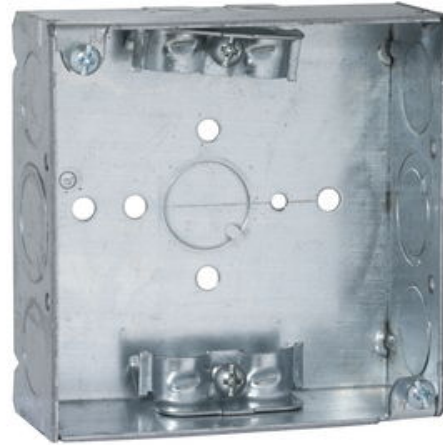

Logistics

Carton Quantity	50
Packaging Type	No Packaging
Pallet Quantity	2500

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - LEED Statement](#)
[Certifications - NEMA OS1](#)
[Sales Drawings - RACO-welded-steel-box-infographic](#)
[SDS - HCC SDS](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-8211-SPEC-EN | REV 6/2024