




4 in. Square Box, Welded, 1-1/2 in. Deep with AC/MC/Flex Clamps, Five 1/2 in. KO's and Two TKO's

By Raco
Catalog # 8213

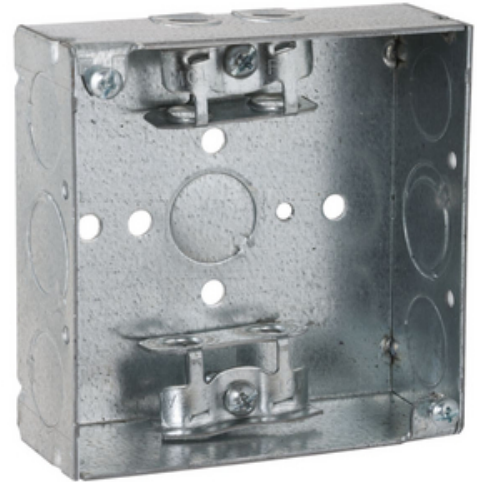

4 in. Square Box, Welded, 1-1/2 in. Deep with AC/MC/Flex Clamps, Five 1/2 in. KO's and Two TKO's

Features

- Use with AC/MC or flexible cable
- Combination screw heads allow quick installation
- Welded construction
- Five 1/2 in. knockouts, 2 TKO knockouts, and 4 cable pryouts
- UL Listed
- 21.0 cu. in. capacity
- UPC barcoded

General

Bracket Type	No Bracket
Catalog Number	8213
Color	Gray
Drawn or Welded	Welded
EU RoHS Indicator	Contact Manufacturer
Fire Resistance	Yes
Knockouts	1/2 in;1/2 - 3/4 in Combination (TKO)
Material	Steel
Number of Gang(s)	2-Gang
Type	Box
UPC	050169002131
Wiring System	Armored Cable/Metal Clad/MCI-A/Flex

Dimensions

Actual Depth	1.932 in
Cubic Capacity	21 cu.in
Depth	1.5 in
Height	4.039 in
Raised Ground	No
Weight	0.756 lb
Width	4.007 in

Electrical Ratings

Power Distribution Features	Fire Rated
-----------------------------	------------

Certifications And Compliance

Certified Listed UL Listed

Logistics

Carton Quantity	30
Packaging Type	No Packaging
Pallet Quantity	1980

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - LEED Statement](#)
[Certifications - NEMA OS1](#)
[Sales Drawings - 8213 Customer Drawing](#)
[SDS - HCC SDS](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-8213-SPEC-EN | REV 6/2024