




4 in. Square Box, Welded, 1-1/2 in. Deep with AC/MC/Flex Clamps, Three 1/2 in. KO's and One TKO, UBS, FS Bracket, Flush

By Raco
Catalog # 8218

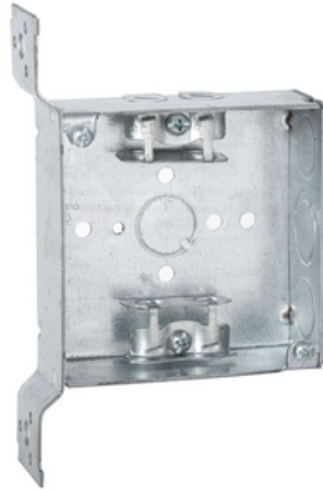

4 in. Square Box, Welded, 1-1/2 in. Deep with AC/MC/Flex Clamps, Three 1/2 in. KO's and One TKO, UBS, FS Bracket, Flush

Features

- Use with AC/MC or flexible cable
- Combination screw heads allow quick installation
- Welded construction
- Three 1/2 in. knockouts, 1 TKO knockout, and 4 cable pryouts
- UL Listed
- 21.0 cu. in. capacity
- FS style bracket, flush
- UPC barcoded

General

Bracket Type	FS, for Metal or Wood Studs
Catalog Number	8218
Color	Gray
Drawn or Welded	Welded
EU RoHS Indicator	Contact Manufacturer
Fire Resistance	Yes
Knockouts	1/2 in.; 1/2 - 3/4 in Combination (TKO)
Material	Steel
Number of Gang(s)	2-Gang
Type	Box
UPC	050169002186
Wiring System	Armored Cable/Metal Clad/MCI-A/Flex

Dimensions

Actual Depth	2.176 in
Cubic Capacity	21 cu.in
Depth	1.5 in
Height	7 in
Raised Ground	No
Weight	0.837 lb
Width	4.25 in

Electrical Ratings

Power Distribution Features Fire Rated

Certifications And Compliance

Certified Listed cULus Listed

Logistics

Carton Quantity 25
Packaging Type No Packaging
Pallet Quantity 1650

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - UL COC - E195978- 3](#)
[Sales Drawings - 8218 Customer Drawing](#)
[SDS - HCC SDS](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-8218-SPEC-EN | REV 6/2024