




4 in. Square Box, Welded, 2-1/8 in. Deep, Ten 1/2 in. KO's and Six TKO's, Raised Ground, UBS, HM Bracket

By Raco
Catalog # 8232HWP

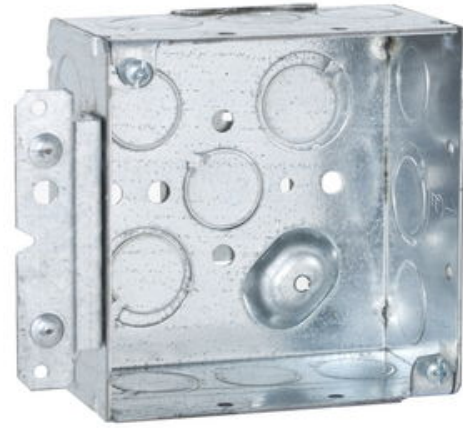

4 in. Square Box, Welded, 2-1/8 in. Deep, Ten 1/2 in. KO's and Six TKO's, Raised Ground, UBS, HM Bracket

Features

- UBS integrated support provides bracing on back of box for wall cavities between 2-1/2 in - 6 in. thickness, H/M
- Combination screw heads allow quick installation
- Welded construction
- Ten 1/2 in. knockouts and six TKO knockouts
- UL Listed
- 30.3 cu. in. capacity
- Raised ground
- Acceptable in 2-hour fire rated walls
- UPC barcoded

General

Bracket Setback	0.375
Bracket Type	H, for Metal or Wood Studs
Color	Gray
Drawn or Welded	Welded
EU RoHS Indicator	Contact Manufacturer
Fire Resistance	Yes
Knockouts	1/2 in.; 1/2 - 3/4 in Combination (TKO)
Material	Steel
Number of Gang(s)	2-Gang
Type	Box
UPC	050169582329
Wiring System	Conduit

Dimensions

Actual Depth	2.676 in
Cubic Capacity	30.3 cu.in
Depth	2.125 in
Height	4.03 in
Raised Ground	Yes
Weight	0.97 lb
Width	4.91 in

Electrical Ratings

Power Distribution Features Fire Rated

Certifications And Compliance

Certified Listed UL Listed

Logistics

Carton Quantity	25
Packaging Type	No Packaging
Pallet Quantity	1375

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - UL COC - E195978- 2](#)
[Sales Drawings - RACO-welded-steel-box-infographic](#)
[SDS - HCC SDS](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-8232HWP-SPEC-EN | REV 6/2024