




4 in. Square Box, Welded, 2-1/8 in. Deep with AC/MC/Flex Clamps, Three 1/2 in. KO's and One TKO, TS Bracket, Flush

By RACO
Catalog # 8241

4 in. Square Box, Welded, 2-1/8 in. Deep with AC/MC/Flex Clamps,
Three 1/2 in. KO's and One TKO, TS Bracket, Flush

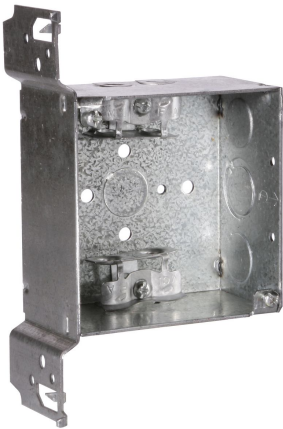

Features

- Welded steel construction with "TS" side-mount bracket with gauging tabs and recessed nailing spurs
- 4 in. square x 2-1/8 in. deep
- BX clamps provided for steel & alum armored cable, MCI cable, MCI-A cable, and flexible conduit
- TKO Knockouts allow for design and installation flexibility
- Supplied with three 1/2 in. and one 1/2-3/4 in. TKO knockouts
- Combination Phillips/slotted screw heads
- 30.3 cu. in. capacity
- Acceptable for use in 2-hour fire rated walls

Specifications

Buy American Compliant	Contact Manufacturer
Certified Listed	UL Listed
Buy America(n) Qualified	Contact Manufacturer

Configuration

Number of Gang(s)	2-Gang
Knockouts	• 1/2 in • 1/2 - 3/4 in Combination (TKO)
Bracket Type	TS, for Metal or Wood Studs

Current

Power Distribution Features	Fire Rated
-----------------------------	------------

Dimensions

Cubic Capacity	30.3 cu.in
Depth	2.125 in

Weight	1.09 lb.
Height	7 in
Width	4.313 in
Actual Depth	2.188 in
Size	4 in
Raised Ground	No

General

Color	Gray
Product Family	4 in. Square Boxes & Extension Rings
Wiring System	Armored Cable/Metal Clad/MCI-A/Flex
Drawn or Welded	Welded
Product Type	Steel Box
UPC	050169002414
Type	Box
Material	Steel
Fire Resistance	Yes

Logistics

Pallet Quantity	1100
Carton Quantity	25
Packaging Type	No Packaging

Product Assets

[Catalog \[English\]](#)
[Catalog \[English\]](#)
[Catalog Page \[English\]](#)
[Catalog Page \[English\]](#)